


Connecting cable with socket

ADOAH040VAS0010E04

Article no longer available - archive entry

Alternative articles: EVT005

When selecting an alternative article and accessories please note that technical data may differ!

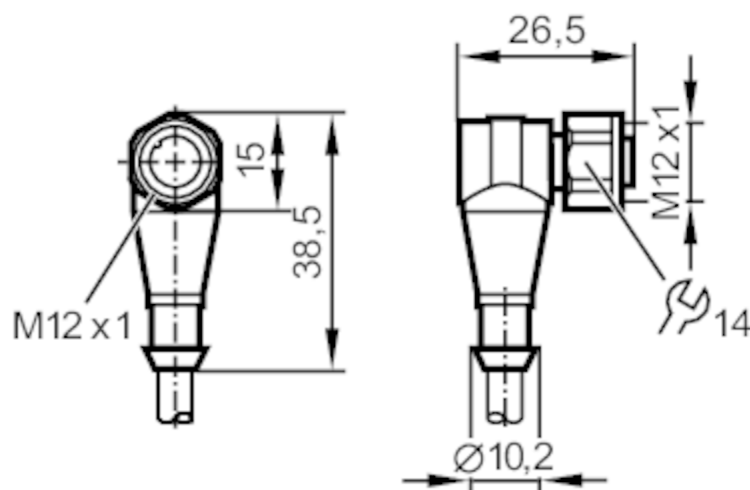

Application

Special feature	Free from silicone; Gold-plated contacts
Free from silicone	yes

Electrical data

Operating voltage	[V]	< 250 AC / < 300 DC
Max. current load total	[A]	4

Operating conditions

Ambient temperature	[°C]	-25...100
Protection		IP 68; IP 69K

Mechanical data

Dimensions	[mm]	26.5 x 15 x 38.5
Materials		PVC
Moulded-body material		PVC
Material nut		stainless steel (1.4404 / 316L)

Remarks

Pack quantity	1 pcs.
---------------	--------

E10701



Connecting cable with socket


ADOAH040VAS0010E04

Electrical connection


Cable: 10 m, PVC, orange, Ø 5.3 mm; 4 x 0.34 mm² (42 x Ø 0.1 mm)

Electrical connection - socket

Connector: 1 x M12, angled; coding: A; Moulded body: PVC; Locking: stainless steel (1.4404 / 316L); Contacts: gold-plated; Tightening torque: 0.7...0.9 Nm

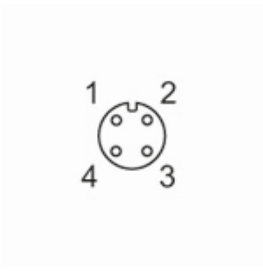

Connection

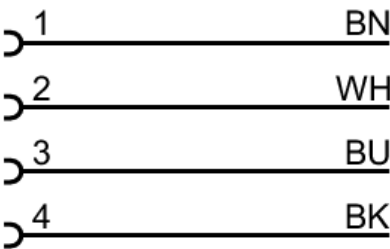

Core colours :
BK = black
BN = brown
BU = blue
WH = white