


Process adapter Varivent

ADAPT IFM-VARIV TYP N (D=68)

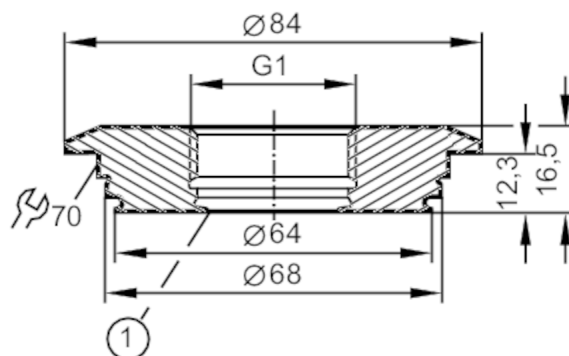

1 sealing edge

EC 1935/2004 FCM 

Application

Pressure rating	[bar]	25
-----------------	-------	----

Tests / approvals

Pressure Equipment Directive	A possible classification to PED depends on the application and has to be carried out by the user / operator.
Safety instructions	The compatibility between medium and product material has to be checked in all applications.

Mechanical data

Weight	[g]	481
Materials (wetted parts)	stainless steel (1.4435 / 316L) ; surface characteristics : Ra<0,4 / Rz 4	
Sensor connection	G 1 internal thread Aseptoflex Vario	
Process connection	Varivent Form N, DN40...DN150 (1,5...6"), Ø 68 mm	
Sealing	metal to metal	
Hygienic equipment class to DIN 11866	H4	

Remarks

Pack quantity	1 pcs.
---------------	--------