

AC2605




AS-Interface control cabinet module

AnalogModule 1A0 ST

Article no longer available - archive entry

Alternative articles: AC2611

When selecting an alternative article and accessories please note that technical data may differ!

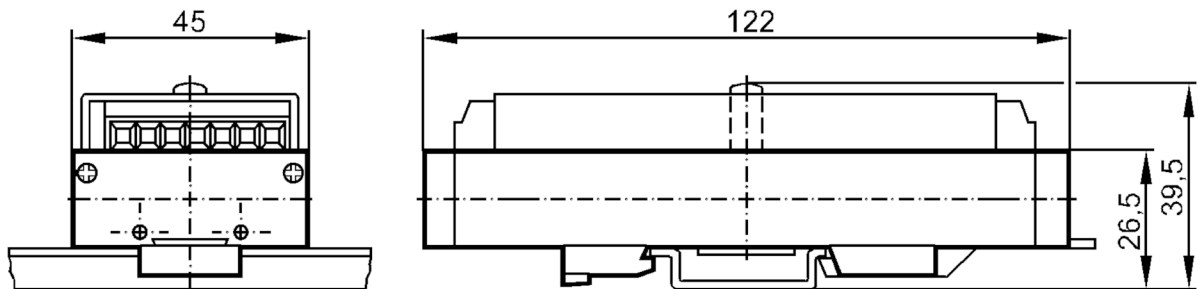

Electrical data

Operating voltage	[V]	26.5...31.6 DC
Current consumption	[mA]	135

Outputs

Electrical design		AS-i
Voltage range DC	[V]	13...36; (to PELV)
Max. current load per output	[mA]	100
Short-circuit proof		yes

Operating conditions

Ambient temperature	[°C]	0...70
Protection		IP 20

Tests / approvals

EMC		EN 50295
-----	--	----------

AS-i classification

AS-i profile		S-7.1
AS-i I/O configuration	[hex]	7
AS-i ID code	[hex]	1
AS-i certificate pending		yes

AC2605



AS-Interface control cabinet module

AnalogModule 1A0 ST

Mechanical data

Type of mounting	mounting on DIN rail and panel; string mounting possible
Materials	PA; PVC

Displays / operating elements

Display	operation	LED, green
	function	1 x LED, yellow
		1 x LED, red


Remarks

Pack quantity	1 pcs.
---------------	--------

Electrical connection

screw terminals:

Connection

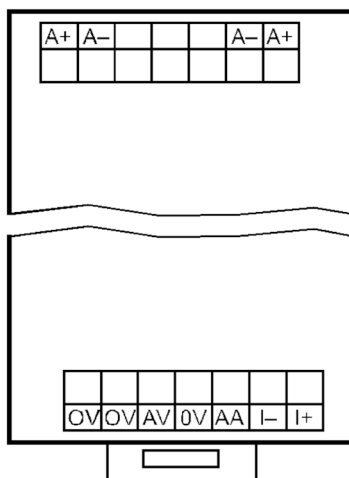

A+	AS-i +
A-	AS-i -
I+	actuator supply +24V
I-	actuator supply 0V
AA	analogue output +
0V	analogue output 0V