


AC2215



AS-Interface repeater

SmartLine25 AS-i Repeater

Article no longer available - archive entry

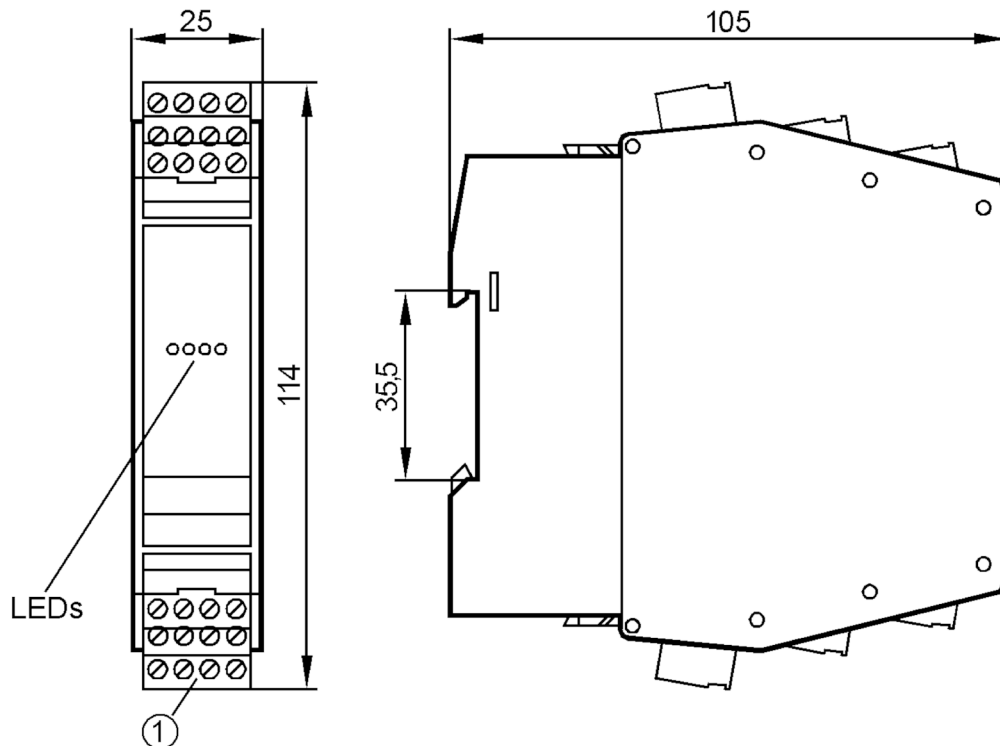

1 COMBICON connector with screw terminals optional



Application	
Application	extension of the AS-i network by another 100 m
Electrical data	
Nominal voltage DC [V]	26.5...31.6
Max. current consumption from AS-i [mA]	2
Undervoltage monitoring	no
Outputs	
Electrical design	AS-i
Electrically separated	yes
Operating conditions	
Ambient temperature [°C]	0...55
Protection	IP 20
Tests / approvals	
EMC	EN 50295
Mechanical data	
Housing	mounting on DIN rail
Materials	PA 6.6

AC2215



AS-Interface repeater

SmartLine25 AS-i Repeater

Displays / operating elements

Display	operation	2 x LED, green
	short circuit	2 x LED, red

Remarks

Remarks	The AS-i extender takes no slave address.
	The total number of slaves per master string remains unchanged.
	No parameter setting necessary.
Pack quantity	1 pcs.

Electrical connection

Connection



A1+	AS-i + string 1
A1-	AS-i - string 1
A2+	AS-i + string 2
A2-	AS-i - string 2