


AC5101



Lower part for AS-Interface module

EMS-BASE RC ST

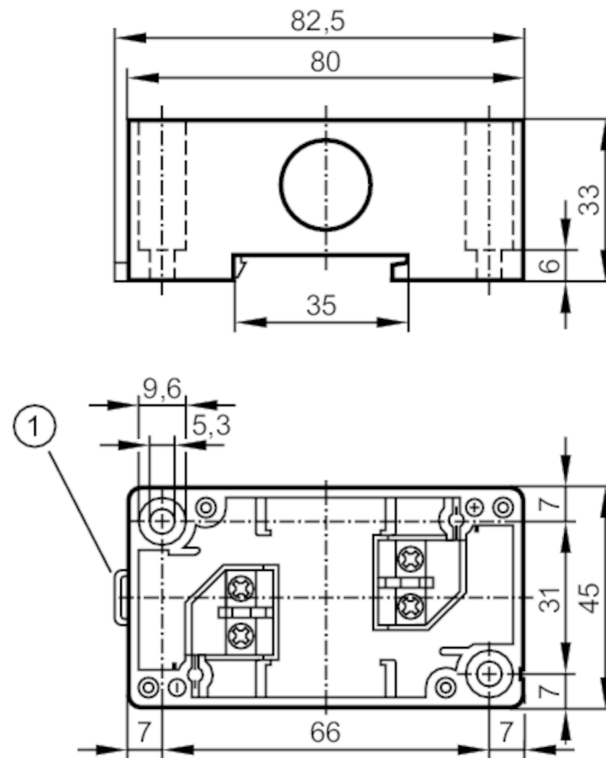

1 locking bolt

Electrical data

Operating voltage [V] 26.5...31.6 DC

Outputs

Electrical design AS-i
Contact rating < 4 A

Operating conditions

Ambient temperature [°C] -25...85
Protection IP 65

Mechanical data

Weight [g] 70.5
Type of mounting mounting on DIN rail and panel
Dimensions [mm] 45 x 82.5 x 33
Materials PBT

Accessories

Accessories (optional) cover:, for AS-i module, AC3000
screw terminal insert:, AC5007

Remarks

Remarks up to 4 M20 cable ports for any T and cross branches
For DIN rail mounting pull the locking bolt outwards using a suitable tool (e.g. screwdriver).

Pack quantity 1 pcs.

Electrical connection

screw terminals: ...2.5 mm²