

E10416



Connecting cable with socket

ADOAH040MSS0005A03

Article no longer available - archive entry



Electrical data		
Operating voltage	[V]	< 250 AC / < 300 DC
Operating conditions		
Ambient temperature	[°C]	-25...90
Protection		IP 67
Mechanical data		
Dimensions	[mm]	27 x 15 x 39
Materials		TPU
Moulded-body material		TPU
Material nut		brass, nickel-plated
Remarks		
Pack quantity		1 pcs.

Electrical connection	
Cable: 5 m, PUR / PVC, orange, Ø 5 mm; 3 x 0.34 mm² (42 x Ø 0.1 mm)	

Electrical connection - socket	
Connector: 1 x M12, angled; coding: A; Moulded body: TPU; Locking: brass, nickel-plated; Tightening torque: 0.5 Nm	




E10416



Connecting cable with socket

ADOAH040MSS0005A03

Connection

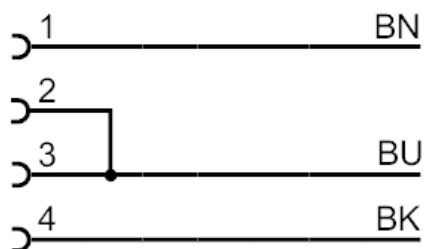

BN =	Core colours :	brown
BK =		black
BU =		blue