


E10435



Connecting cable with socket

ADOGH040MSS0015A04

Article no longer available - archive entry

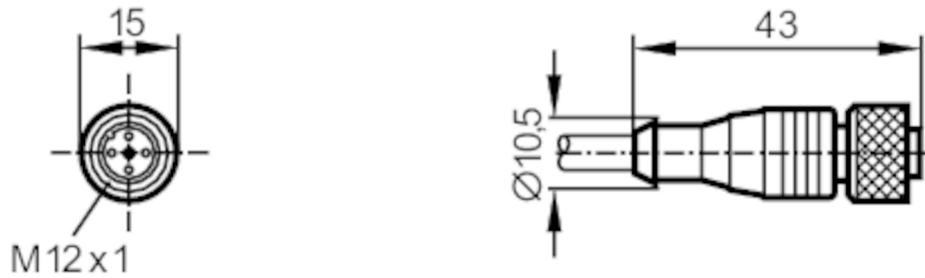

Electrical data

Operating voltage [V] < 250 AC / < 300 DC

Operating conditions

Ambient temperature [°C] -25...90

Protection IP 67

Mechanical data

Dimensions [mm] 15 x 15 x 43

Materials TPU

Moulded-body material TPU

Material nut brass, nickel-plated

Remarks

 
Pack quantity 1 pcs.

Electrical connection

Cable: 15 m, PUR / PVC, orange, Ø 5 mm; 4 x 0.25 mm² (32 x Ø 0.1 mm)

Electrical connection - socket

Connector: 1 x M12, straight; Moulded body: TPU; Locking: brass, nickel-plated




E10435



Connecting cable with socket

ADOGH040MSS0015A04

Connection

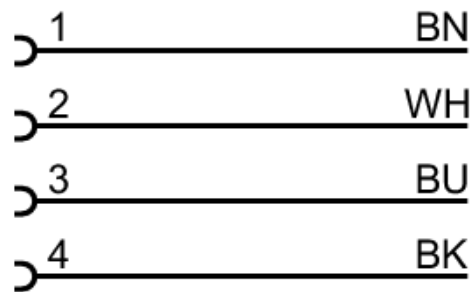

Core colours :

BN =	brown
BK =	black
BU =	blue
WH =	white