

E10446




Splitter box

ZDO8H059MSS0000-00STAM120MSS

Article no longer available - archive entry

Alternative articles: EBC010
When selecting an alternative article and accessories please note that technical data may differ!

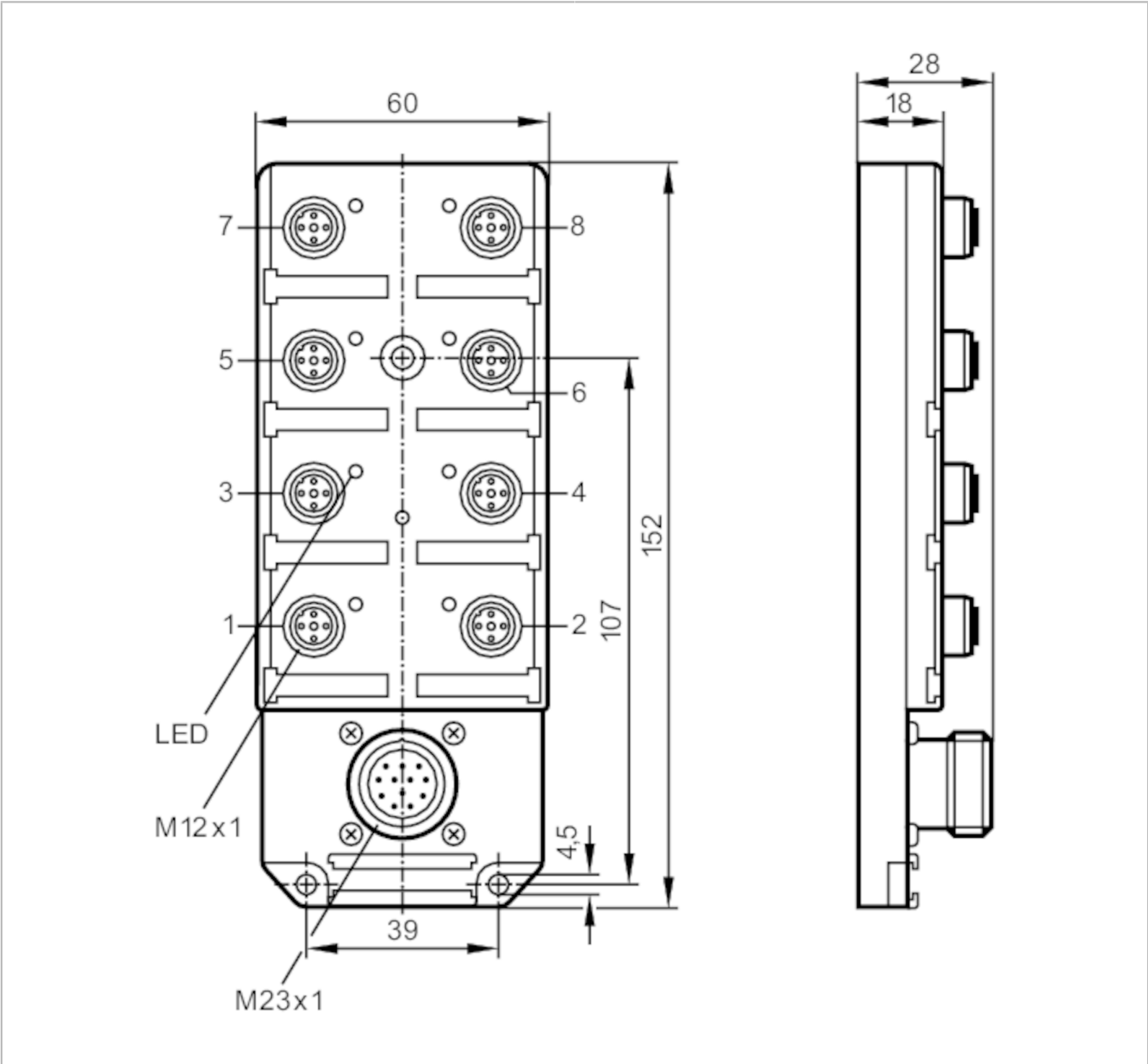

Application		
Special feature		Free from silicone; Gold-plated contacts
Free from silicone		yes
Electrical data		
Operating voltage	[V]	10...30 DC
Protection class		II
Max. current load per module/slot	[A]	4

E10446



Splitter box

ZDO8H059MSS0000-00STAM120MSS

Max. current load total	[A]	12
-------------------------	-----	----

Operating conditions

Ambient temperature	[°C]	-15...80
---------------------	------	----------

Protection	IP 67
------------	-------

Mechanical data

Dimensions	[mm]	28 x 60 x 152
------------	------	---------------

Materials	TPU
-----------	-----

Moulded-body material	TPU
-----------------------	-----

Number of ports splitter box	8
------------------------------	---

Connector type	M12
----------------	-----

Displays / operating elements

Display	switching status	8 x LED, yellow
---------	------------------	-----------------

	operation	1 x LED, green
--	-----------	----------------

Remarks

Pack quantity	1 pcs.
---------------	--------

Electrical connection - Connection

Connector: 1 x M23; Moulded body: TPU; Contacts: gold-plated; Tightening torque: 0.5 Nm




E10446



Splitter box

ZDO8H059MSS0000-00STAM120MSS

Connection

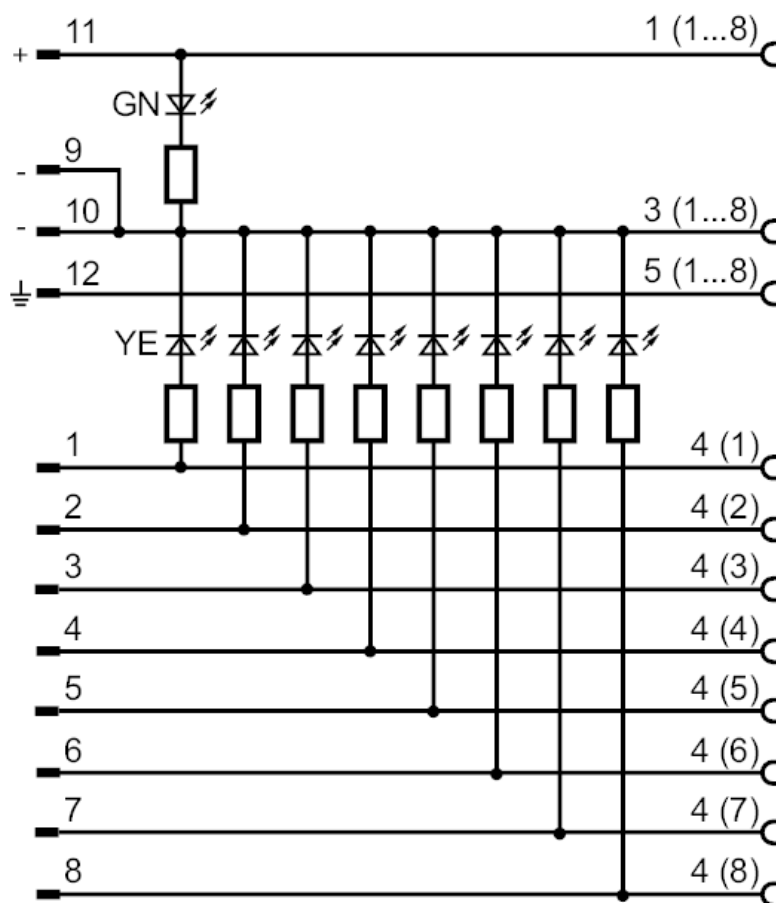

Electrical connection - slot

Connector: 8 x M12; coding: A; Moulded body: TPU; Contacts: gold-plated; Tightening torque: 0.5 Nm

