

E10520




Connecting cable with socket

ADOGH040MSS0002A03

Article no longer available - archive entry

Alternative article: EVC001 When selecting an alternative article and accessories please note that technical data may differ! – When selecting an alternative article and accessories please note that technical data may differ!

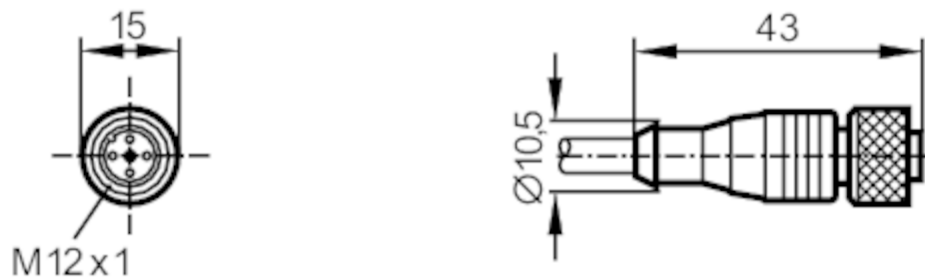

Electrical data

Operating voltage [V] < 250 AC / < 300 DC

Operating conditions

Ambient temperature [°C] -25...90

Protection IP 67

Mechanical data

Dimensions [mm] 15 x 15 x 43

Materials TPU

Material nut brass, nickel-plated

Remarks

Pack quantity 1 pcs.

Electrical connection

Cable: 2 m, PUR / PVC, orange, Ø 5 mm; 3 x 0.34 mm² (42 x Ø 0.1 mm)

Electrical connection - socket

Connector: 1 x M12, straight; Moulded body: TPU; Locking: brass, nickel-plated




E10520



Connecting cable with socket

ADOGH040MSS0002A03

Connection

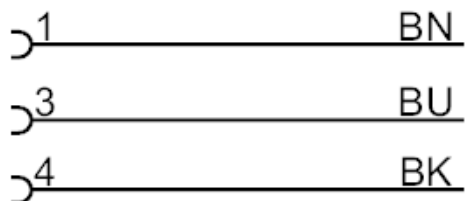

Core colours :

BN = brown
BK = black
BU = blue

Article no longer available - archive entry

Alternative article: EVC001 When selecting an alternative article and accessories please note that technical data may differ! – When selecting an alternative article and accessories please note that technical data may differ!