


E10558



Connecting cable with socket

ADOGH040MSS0010E03

Article no longer available - archive entry

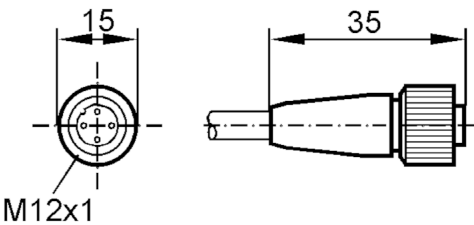

Electrical data		
Operating voltage	[V]	< 250 AC / < 300 DC
Operating conditions		
Ambient temperature	[°C]	-20...70
Protection		IP 67
Mechanical data		
Dimensions	[mm]	15 x 15 x 35
Materials		PA 6.6
Moulded-body material		PA 6.6
Material nut		POM
Remarks		
Pack quantity		1 pcs.
Electrical connection		
Cable: 10 m, PVC, yellow, Ø 5.84 mm; 3 x 0.34 mm² / AWG 22		
Electrical connection - socket		

Connector: 1 x M12, straight; coding: A; Moulded body: PA 6.6; Locking: POM



E10558



Connecting cable with socket

ADOGH040MSS0010E03

Connection



	Core colours :
BK =	black
BN =	brown
BU =	blue