


Adapter plug

ESTGH040MSS0,08E04 (PG13,5)

Article no longer available - archive entry

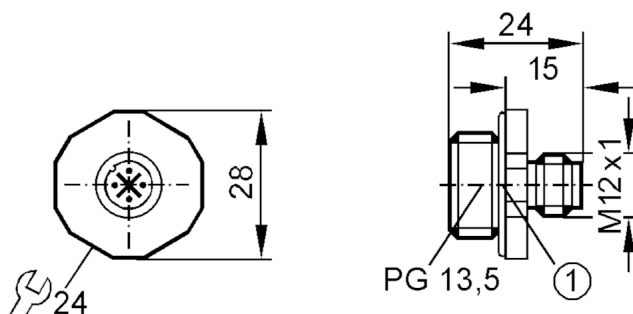

1 O-ring

Electrical data

Operating voltage	[V]	< 250 AC / < 300 DC
-------------------	-----	---------------------

Operating conditions

Ambient temperature	[°C]	-40...85
---------------------	------	----------

Protection	IP 67
------------	-------

Mechanical data

Mounting thread	PG 13.5
-----------------	---------

Materials	brass nickel-plated
-----------	---------------------

Moulded-body material	brass, nickel-plated
-----------------------	----------------------

Remarks

Pack quantity	1 pcs.
---------------	--------

Electrical connection

Cable: 0.08 m, PVC; 4 x 0.34 mm²

Electrical connection - plug

Connector: 1 x M12; coding: A; Moulded body: brass, nickel-plated



E10571



Adapter plug

ESTGH040MSS0,08E04 (PG13,5)

Connection

1	BN
2	WH
3	BU
4	BK