

E10622




Wirable socket

SDOAH050MSSFKPG

Article no longer available - archive entry

Alternative articles: E11512

When selecting an alternative article and accessories please note that technical data may differ!

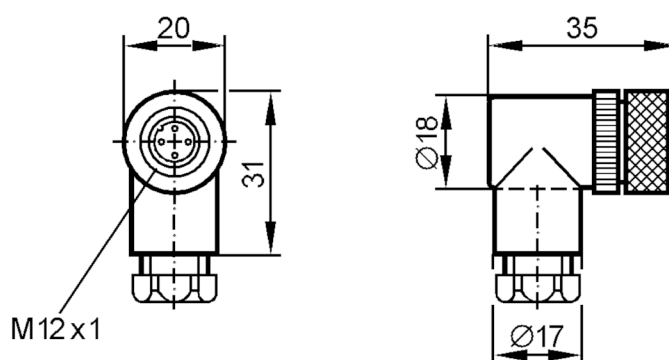

Electrical data

Operating voltage	[V]	< 50 AC/DC
-------------------	-----	------------

Operating conditions

Ambient temperature	[°C]	-25...90
Protection		IP 67

Mechanical data

Dimensions	[mm]	35 x 20 x 31
Materials		PA
Moulded-body material		PA
Material nut		brass, nickel-plated

Remarks

Pack quantity		1 pcs.
---------------	--	--------

E10622



Wirable socket


SDOAH050MSSFKPG

Electrical connection

terminals: ...0.75 mm²; Cable sheath: Ø 6...8 mm

Electrical connection - socket

Connector: 1 x M12, angled; coding: A; Moulded body: PA; Locking: brass, nickel-plated

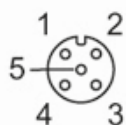

Connection

