

E10791




Wirable socket

SDOGH040MSSFKPG

Article no longer available - archive entry

Alternative articles: E11508

When selecting an alternative article and accessories please note that technical data may differ!

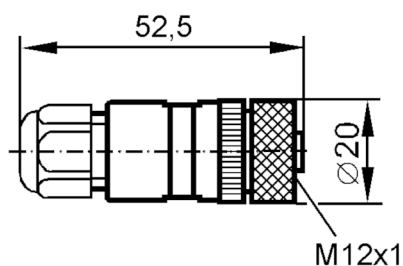

Electrical data

Frequency AC	[Hz]	47...63
Operating voltage	[V]	< 125 AC / < 150 DC

Operating conditions

Ambient temperature	[°C]	-25...90
Protection		IP 67

Mechanical data

Dimensions	[mm]	20 x 20 x 52.5
Materials		PA
Moulded-body material		PA
Material nut		brass, nickel-plated

Remarks

Pack quantity		1 pcs.
---------------	--	--------

E10791



Wirable socket

SDOGH040MSSFKPG

Electrical connection

terminals: ...0.75 mm²; Cable sheath: Ø 4...6 mm

Electrical connection - socket

Connector: 1 x M12, straight; coding: A; Moulded body: PA; Locking: brass, nickel-plated



Connection

