


E10801



Connecting cable with socket

ADOGH040VAS0020E04

Article no longer available - archive entry

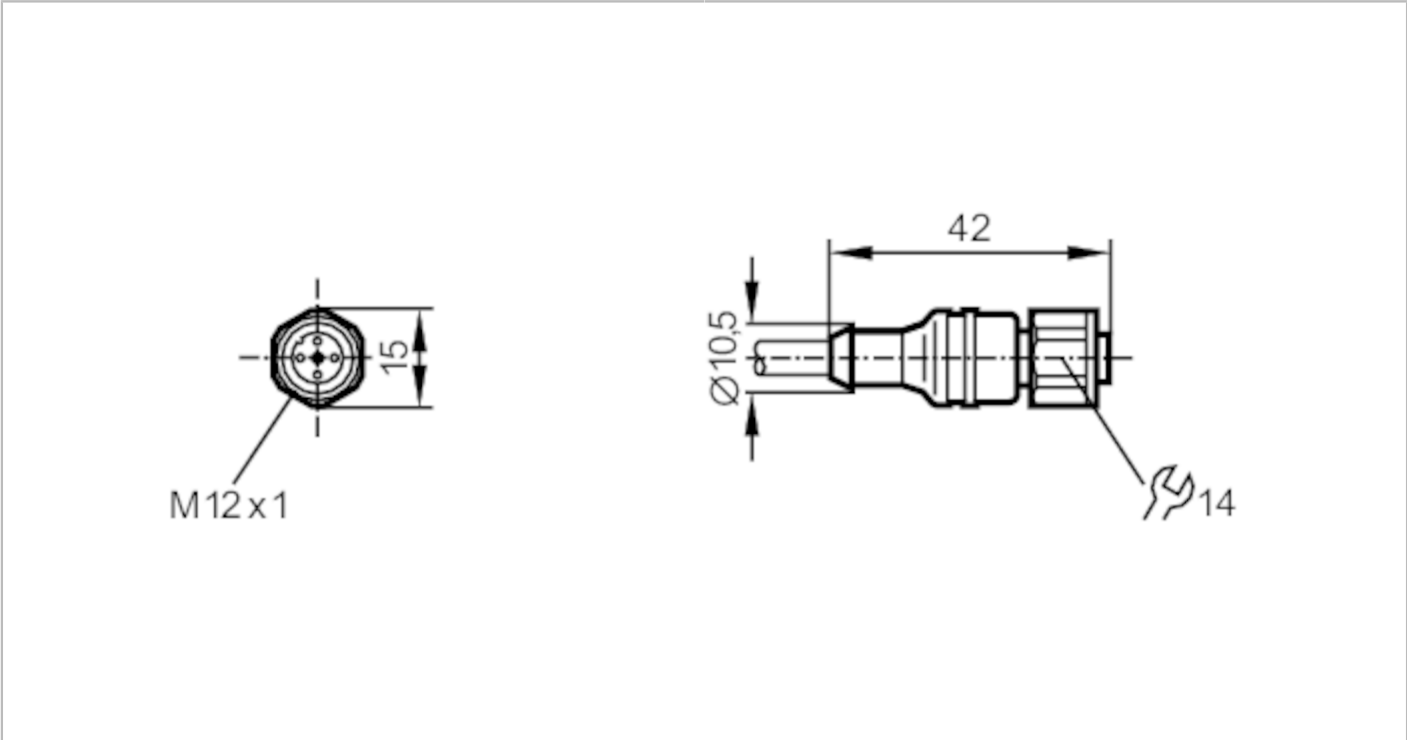

Application	
Special feature	Gold-plated contacts
Electrical data	
Operating voltage [V]	< 250 AC / < 300 DC
Operating conditions	
Ambient temperature [°C]	-25...70
Protection	IP 67
Mechanical data	
Dimensions [mm]	15 x 15 x 42
Materials	TPU
Moulded-body material	TPU
Material nut	stainless steel (316L/1.4404)
Remarks	
Pack quantity	1 pcs.

E10801



Connecting cable with socket

ADOGH040VAS0020E04

Electrical connection


Cable: 20 m, PVC, orange; 4 x 0.25 mm² (32 x Ø 0.1 mm)

Electrical connection - socket

Connector: 1 x M12, straight; coding: A; Moulded body: TPU; Locking: stainless steel (316L/1.4404); Contacts: gold-plated



Connection

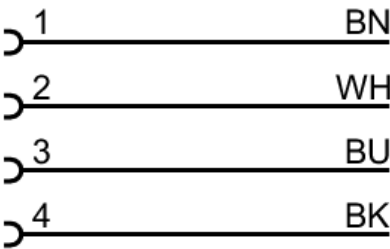

Core colours :
BK = black
BN = brown
BU = blue
GY = grey