

E10910




Connecting cable with socket

ADOAH040SCS0005I04

Article no longer available - archive entry

Alternative articles: EVW005

When selecting an alternative article and accessories please note that technical data may differ!

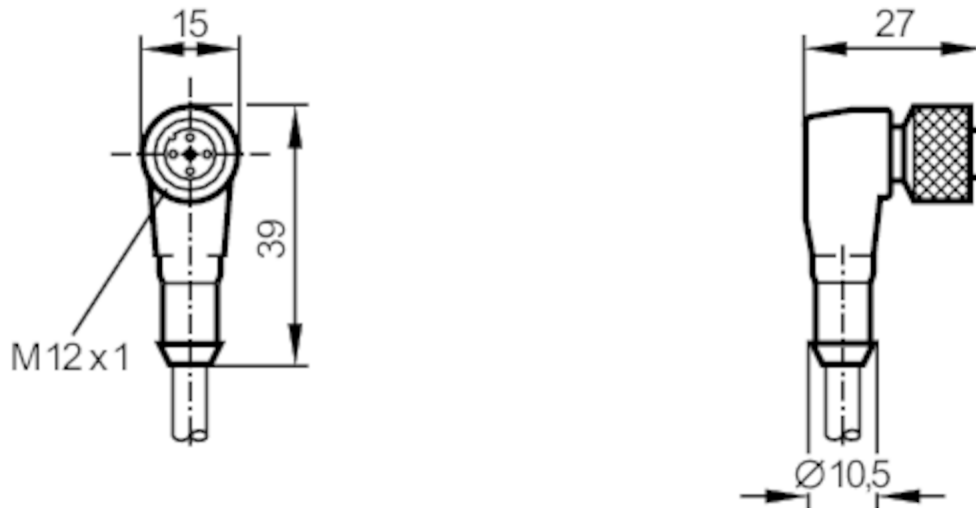

Application

| | |
|--------------------|--|
| Special feature | Free from silicone; Halogen-free; Gold-plated contacts |
| Free from silicone | yes |

Electrical data

| | |
|-----------------------------|---------------------|
| Operating voltage [V] | < 250 AC / < 300 DC |
| Max. current load total [A] | 4 |

Operating conditions

| | |
|--------------------------|----------|
| Ambient temperature [°C] | -25...90 |
| Protection | IP 68 |

Mechanical data

| | |
|-----------------------|---------------------|
| Dimensions [mm] | 27 x 15 x 39 |
| Materials | TPU |
| Moulded-body material | TPU |
| Material nut | brass, anti-spatter |

Remarks

| | |
|---------------|--------|
| Pack quantity | 1 pcs. |
|---------------|--------|

E10910



Connecting cable with socket

 
ADOAH040SCS0005I04

Electrical connection


Cable: 5 m, PUR, Halogen-free, black, Ø 4.8 mm; cross-linked; 4 x 0.34 mm²

Electrical connection - socket

Connector: 1 x M12, angled; Moulded body: TPU; Locking: brass, anti-spatter; Contacts: gold-plated; Tightening torque: 0.5 Nm



Connection

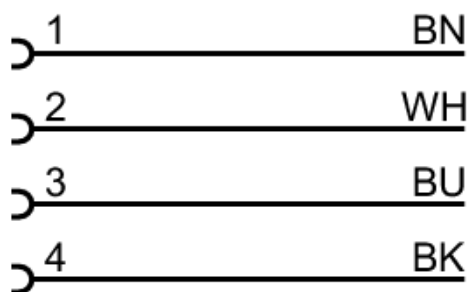

Core colours :

| | |
|------|-------|
| BK = | black |
| BN = | brown |
| BU = | blue |
| WH = | white |