


Connection cable

VDOAH042MSS00,6H03STGF030MSS

Article no longer available - archive entry

Alternative articles: E11347

When selecting an alternative article and accessories please note that technical data may differ!

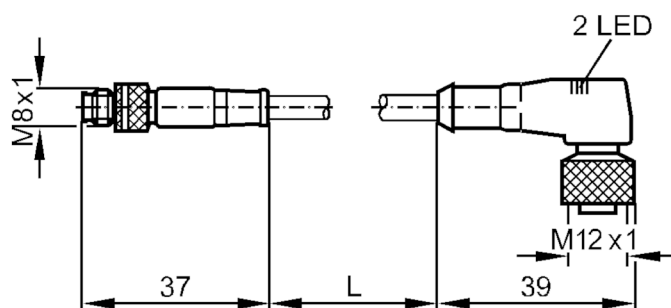

Application

Special feature

Halogen-free

Electrical data

Operating voltage

[V]

10...30 DC

Protection class

III

Operating conditions

Ambient temperature

[°C]

-25...90

Protection

IP 67

Mechanical data

Materials

TPU

Moulded-body material

TPU

Material nut

brass, nickel-plated

Displays / operating elements

Display

switching status

1 x LED, yellow

operation

1 x LED, green

Remarks

Pack quantity

1 pcs.

Electrical connection - plug

Connector: 1 x M8, straight; coding: A; Moulded body: TPU; Locking: brass, nickel-plated



E10940



Connection cable

VDOAH042MSS00,6H03STGF030MSS

Electrical connection

Cable: 0.6 m, TPU, Halogen-free; 3 x 0.34 mm² (42 x Ø 0.1 mm)

Connection



Electrical connection - socket

Connector: 1 x M12, angled; coding: A; Moulded body: TPU; Locking: brass, nickel-plated

