

# E10297




## Connecting cable with socket

ADOAH042MSS0002F03

Article no longer available - archive entry

Alternative articles: E10912  
When selecting an alternative article and accessories please note that technical data may differ!

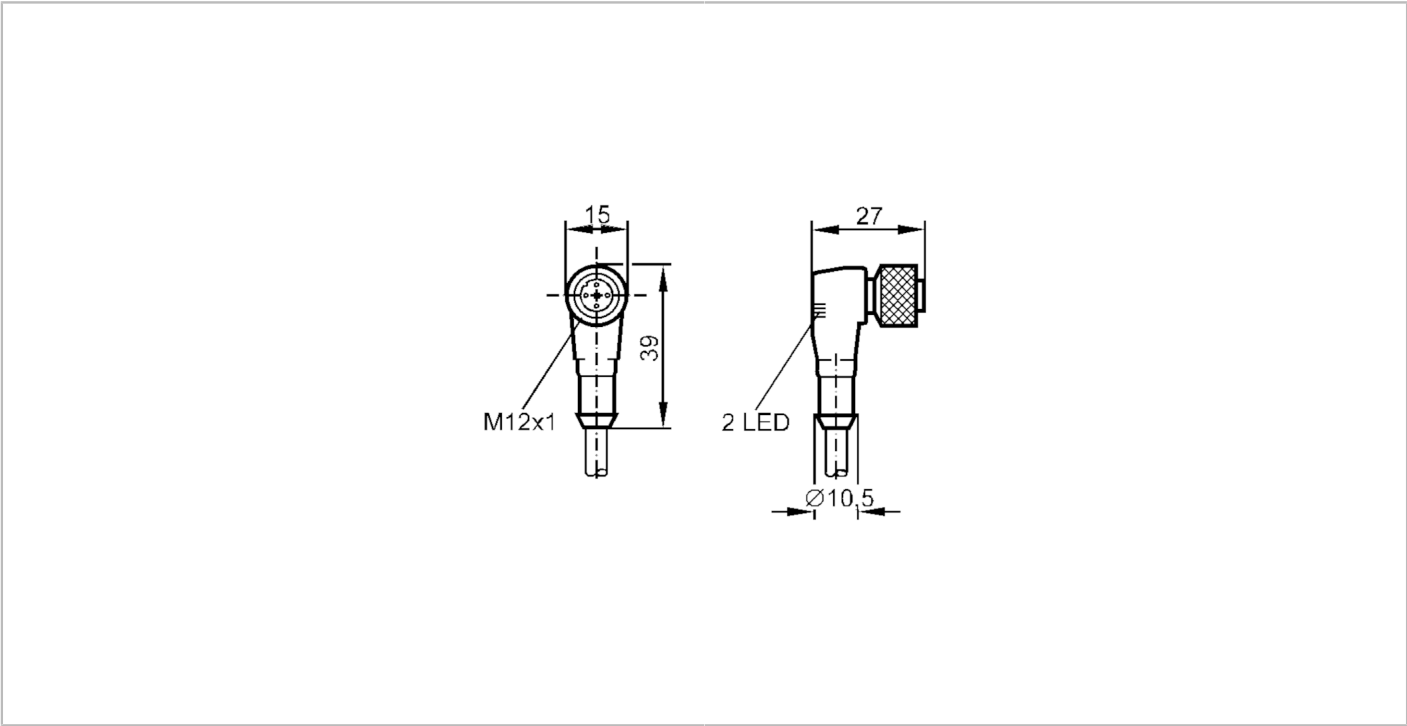

| Electrical data       |      |                     |
|-----------------------|------|---------------------|
| Operating voltage     | [V]  | 10...30 DC          |
| Outputs               |      |                     |
| Electrical design     |      | PNP                 |
| Operating conditions  |      |                     |
| Ambient temperature   | [°C] | -25...90            |
| Protection            |      | IP 67               |
| Mechanical data       |      |                     |
| Dimensions            | [mm] | 27 x 15 x 39        |
| Materials             |      | TPU transparent     |
| Moulded-body material |      | TPU, transparent    |
| Material nut          |      | brass, anti-spatter |
| Remarks               |      |                     |
| Pack quantity         |      | 1 pcs.              |

# E10297



## Connecting cable with socket

ADOAH042MSS0002F03

### Electrical connection


Cable: 2 m, PVC, orange, Ø 5 mm; cross-linked; 3 x 0.34 mm<sup>2</sup> (19 x Ø 0.15 mm )

### Electrical connection - socket

Connector: 1 x M12, angled; coding: A; Moulded body: TPU, transparent; Locking: brass, anti-spatter



### Connection

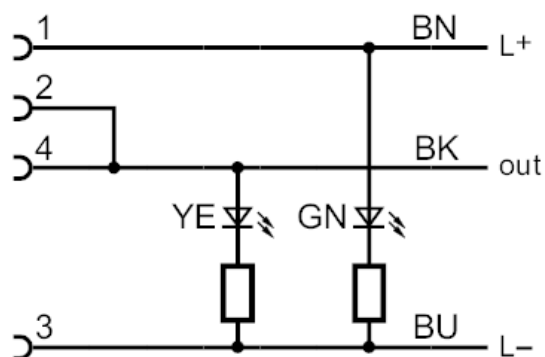

BN = Core colours :  
brown  
BK = black  
BU = blue