


E10359



Connecting cable with socket


ADOGB030PLS0010E03

Article no longer available - archive entry

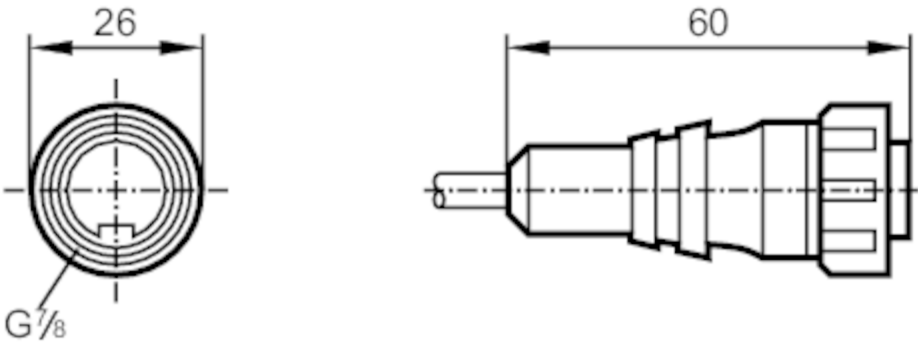

Electrical data		
Operating voltage	[V]	< 250 AC
Operating conditions		
Ambient temperature	[°C]	-40...90
Protection		IP 68
Mechanical data		
Dimensions	[mm]	26 x 26 x 60
Materials		TPU
Moulded-body material		TPU
Material nut		PA 6 GV
Remarks		
Pack quantity		1 pcs.
Electrical connection		
Cable: 10 m, PVC, orange, Ø 7.2 mm; 3 x 0.75 mm² (22 x Ø 0.2 mm)		
Electrical connection - socket		

 Connector: 1 x 7/8", straight; coding: A; Moulded body: TPU; Locking: PA 6 GV




E10359



Connecting cable with socket

ADOGB030PLS0010E03

Connection

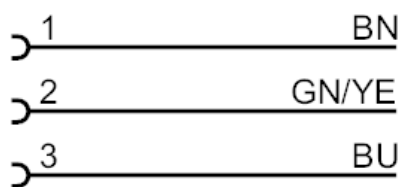

BN =	Core colours :
BU =	brown
GN/YE =	blue
	green/yellow