

E11456




Connection cable

VDOAH040MSS00,3H04STGH040MSS

Article no longer available - archive entry

Alternative articles: EVC015

When selecting an alternative article and accessories please note that technical data may differ!

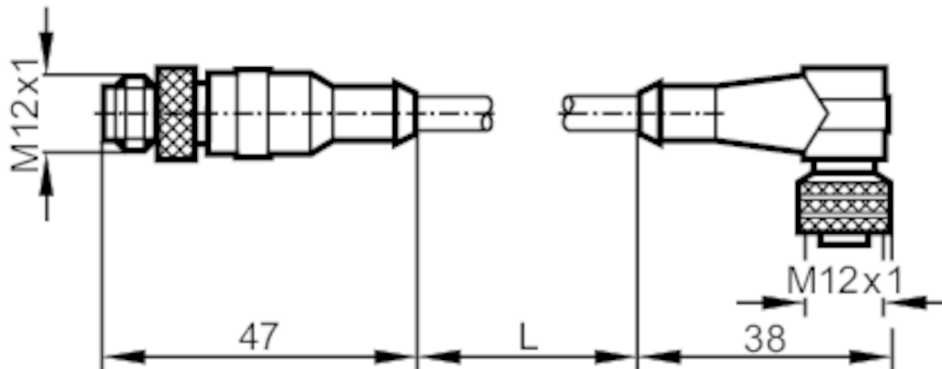

Application	
Special feature	Free from silicone; Halogen-free; Gold-plated contacts
Free from silicone	yes
Electrical data	
Operating voltage [V]	< 250 AC / < 300 DC
Max. current load total [A]	3
Operating conditions	
Ambient temperature [°C]	-25...85
Protection	IP 68
Mechanical data	
Materials	PUR
Moulded-body material	PUR
Material nut	brass, nickel-plated
Remarks	
Pack quantity	1 pcs.
Electrical connection - plug	
Connector: 1 x M12, straight; Moulded body: PUR; Locking: brass, nickel-plated; Contacts: gold-plated; Tightening torque: 0.7...0.9 Nm	

E11456



Connection cable


VDOAH040MSS00,3H04STGH040MSS



Electrical connection

Cable: 0.3 m, PUR, Halogen-free, black, \varnothing 4.7 mm; 4 x 0.34 mm² (42 x \varnothing 0.1 mm)

Connection

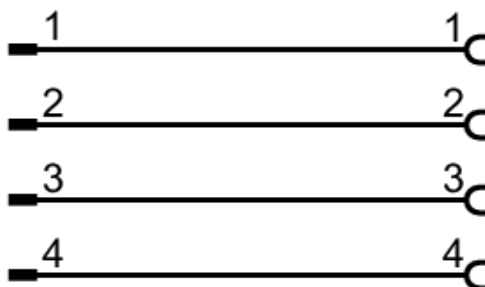

Electrical connection - socket

Connector: 1 x M12, angled; Moulded body: PUR; Locking: brass, nickel-plated; Contacts: gold-plated; Tightening torque: 0.7...0.9 Nm

