



Connecting cable with socket

ADOAF032MSS0005H03

Article no longer available - archive entry

Alternative articles: EVC148

When selecting an alternative article and accessories please note that technical data may differ!



Application		
Special feature	Free from silicone; Halogen-free; Gold-plated contacts	
Free from silicone		
yes		
Electrical data		
Operating voltage	[V]	10...30 DC
Protection class		III
Max. current load total	[A]	3
Outputs		
Electrical design		PNP
Operating conditions		
Ambient temperature	[°C]	-25...85
Protection		IP 68
Mechanical data		
Dimensions	[mm]	17 x 10 x 26
Materials		PUR
Moulded-body material		PUR
Material nut		brass, nickel-plated

E11493



Connecting cable with socket

ADOAF032MSS0005H03

Displays / operating elements

Display	switching status	1 x LED, yellow
	operation	1 x LED, green

Remarks

Pack quantity	1 pcs.
---------------	--------

 
Electrical connection

Cable: 5 m, PUR, Halogen-free, black, Ø 4.1 mm; 3 x 0.25 mm² (32 x Ø 0.1 mm)


Electrical connection - socket

Connector: 1 x M8, angled; coding: A; Moulded body: PUR; Locking: brass, nickel-plated; Contacts: gold-plated; Tightening torque: 0.6...0.7 Nm

Connector: 1 x M8, angled; coding: A; Moulded body: PUR; Locking: brass, nickel-plated; Contacts: gold-plated; Tightening torque: 0.6...0.7 Nm



Connection

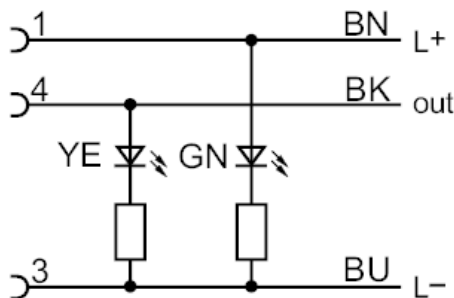

BK = black
BN = brown
BU = blue

Core colours :