


E11693



Connecting cable with socket

ADOAH040MSN0002A04

Article no longer available - archive entry

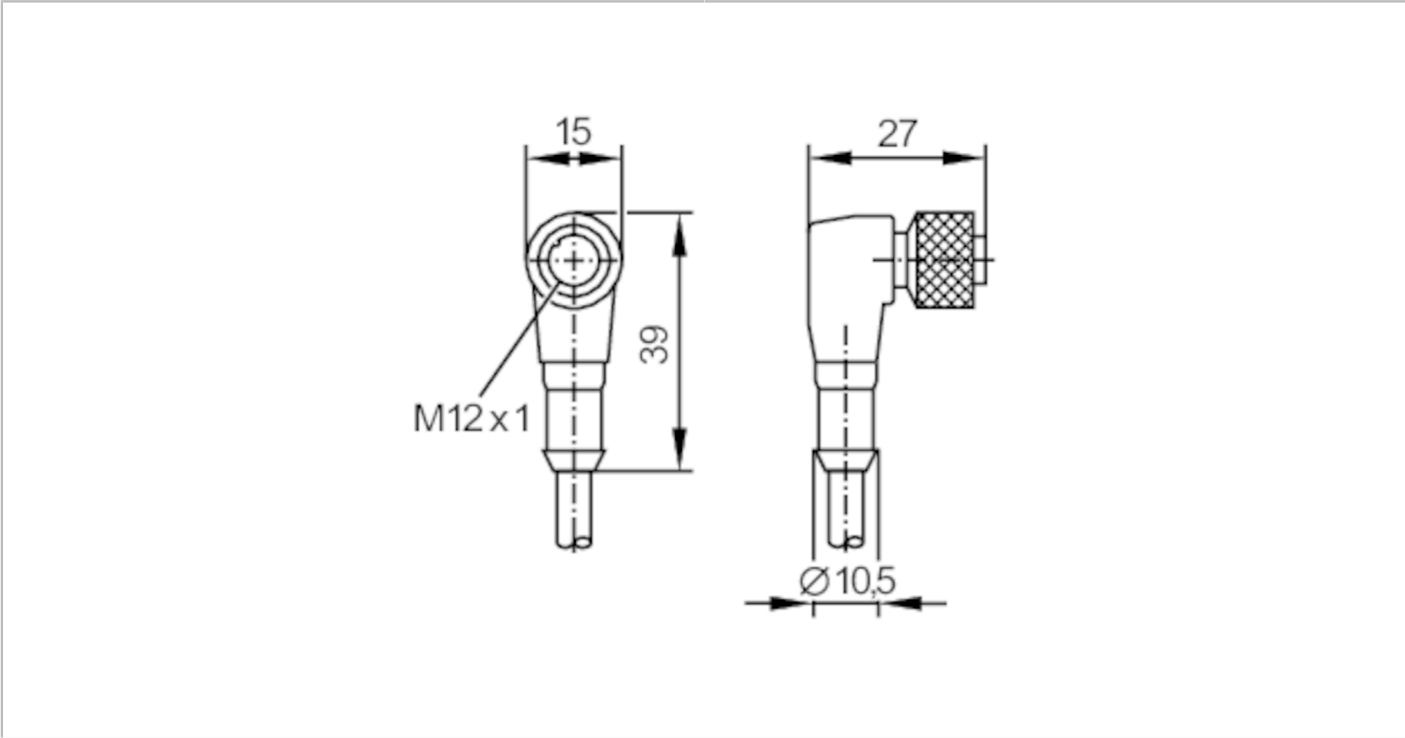

Application	
Application	Ex zone 1
Electrical data	
Operating voltage [V]	< 15 DC
Operating conditions	
Ambient temperature [°C]	-25...90
Protection	IP 67
Mechanical data	
Dimensions [mm]	27 x 15 x 39
Materials	TPU
Moulded-body material	TPU
Material nut	brass, nickel-plated
Remarks	
Remarks	When using sockets in hazardous areas (ATEX) there are special requirements regarding wiring. The requirements of the applicable installation regulations must be absolutely adhered to by the user on his own responsibility.
Pack quantity	1 pcs.

# E11693



## Connecting cable with socket


ADOAH040MSN0002A04

### Electrical connection


Cable: 2 m, PUR / PVC, blue, Ø 5 mm; 5 x 0.34 mm² (42 x Ø 0.1 mm )

### Electrical connection - socket

Connector: 1 x M12, angled; coding: A; Moulded body: TPU; Locking: brass, nickel-plated

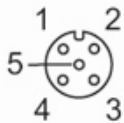

### Connection

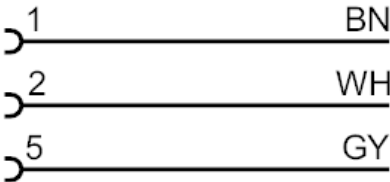

BN = Core colours : brown  
GY = grey  
WH = white