

# E11732




## Splitter box

ZDO8H050MSS0005H11

Article no longer available - archive entry

replaced by: EBC022

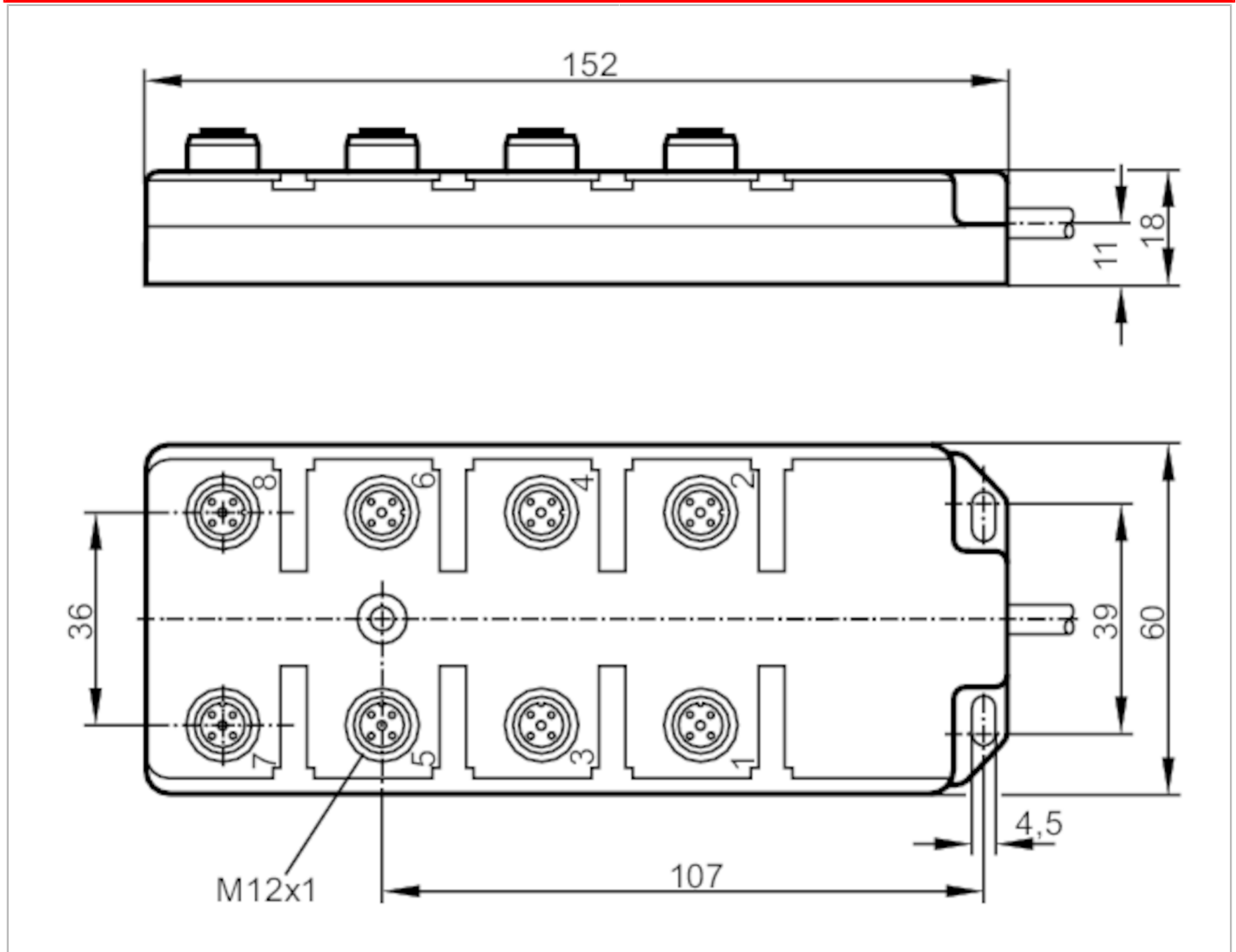

Application	
Special feature	Free from silicone; Halogen-free; Gold-plated contacts
Free from silicone	yes
Electrical data	
Operating voltage [V]	< 60 AC / < 75 DC
Protection class	II
Max. current load per module/slot [A]	4
Max. current load total [A]	12
Operating conditions	
Ambient temperature [°C]	-15...80
Protection	IP 67

# E11732



## Splitter box

ZDO8H050MSS0005H11

### Mechanical data

Materials	TPU
Number of ports splitter box	8
Connector type	M12

### Remarks


Pack quantity	1 pcs.
---------------	--------

### Electrical connection

Cable: 5 m, PUR, Halogen-free, black,  $\varnothing$  11.6 mm; 16 x 0.5 mm<sup>2</sup> (63 x  $\varnothing$  0.1 mm ) + 3 x 1.0 mm<sup>2</sup> (127 x  $\varnothing$  0.1 mm )

### Electrical connection - slot

Connector: 8 x M12; Moulded body: TPU; Contacts: gold-plated; Tightening torque: 0.5 Nm

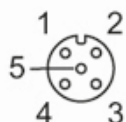

# E11732



## Splitter box

ZDO8H050MSS0005H11

### Connection

<u>BN</u>	1 (1...8)	C
<u>BU</u>	3 (1...8)	C
<u>GN/YE</u>	5 (1...8)	C
<u>GY/PK</u>	2 (1)	C
<u>RD/BU</u>	2 (2)	C
<u>WH/GN</u>	2 (3)	C
<u>BN/GN</u>	2 (4)	C
<u>WH/YE</u>	2 (5)	C
<u>YE/BN</u>	2 (6)	C
<u>WH/GY</u>	2 (7)	C
<u>GY/BN</u>	2 (8)	C
<u>WH</u>	4 (1)	C
<u>GN</u>	4 (2)	C
<u>YE</u>	4 (3)	C
<u>GY</u>	4 (4)	C
<u>PK</u>	4 (5)	C
<u>RD</u>	4 (6)	C
<u>BK</u>	4 (7)	C
<u>VT</u>	4 (8)	C

#### Core colours :

BN =	brown
BU =	blue
GN =	green
GY =	grey
PK =	pink
RD =	red
WH =	white
YE =	yellow

Article no longer available - archive entry

# E11732

## Splitter box

ZDO8H050MSS0005H11



replaced by: EBC022