


# E11843



## Connecting cable with socket

ADOAH050MSN0025A05

Article no longer available - archive entry

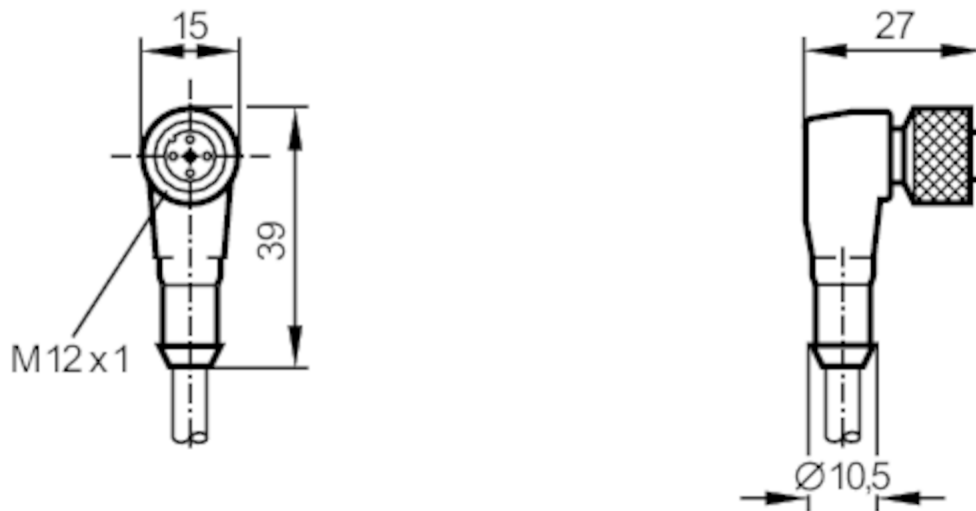

### Application

Application Ex zone 1

### Electrical data

Operating voltage [V] 10...30 DC

### Operating conditions

Ambient temperature [°C] -25...90

Protection IP 67

### Safety classification

Max. internal capacitance [nF] 1.9

Max. internal inductance [µH] 14.75

### Mechanical data

Dimensions [mm] 27 x 15 x 39

Materials TPU

Moulded-body material TPU

Material nut brass, nickel-plated

### Remarks

Remarks When using sockets in hazardous areas (ATEX) there are special requirements regarding wiring. The requirements of the applicable installation regulations must be absolutely adhered to by the user on his own responsibility.

Pack quantity 1 pcs.

# E11843



## Connecting cable with socket


ADOAH050MSN0025A05

### Electrical connection


Cable: 25 m, PUR / PVC, blue, Ø 6 mm; 5 x 0.34 mm<sup>2</sup> (42 x Ø 0.1 mm )

### Electrical connection - socket

Connector: 1 x M12, angled; Moulded body: TPU; Locking: brass, nickel-plated

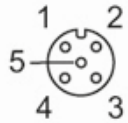

### Connection

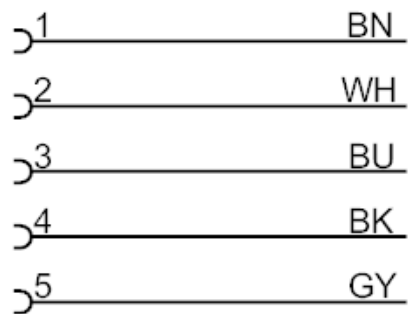

#### Core colours :

BK =	black
BN =	brown
BU =	blue
GY =	grey
WH =	white