

E11112




Wirable socket

SDOAH050MSSFKPG

Article no longer available - archive entry

Alternative articles: E11512

When selecting an alternative article and accessories please note that technical data may differ!

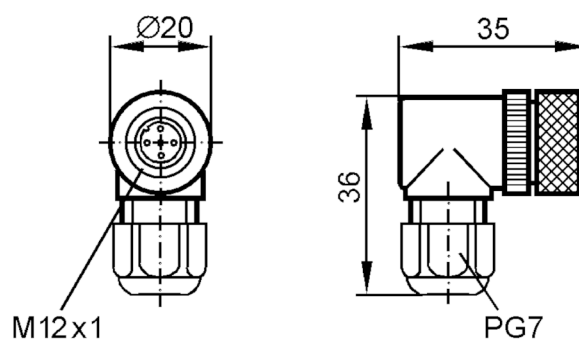

Electrical data

Operating voltage	[V]	< 30 AC / < 36 DC
-------------------	-----	-------------------

Operating conditions

Ambient temperature	[°C]	-25...90
---------------------	------	----------

Protection		IP 67
------------	--	-------

Mechanical data

Dimensions	[mm]	35 x 20 x 36
------------	------	--------------

Materials		PA
-----------	--	----

Moulded-body material		PA
-----------------------	--	----

Material nut		brass, nickel-plated
--------------	--	----------------------

Remarks

Pack quantity		1 pcs.
---------------	--	--------

E11112



Wirable socket

SDOAH050MSSFKPG

Electrical connection

terminals: ...0.75 mm²; Cable gland: PG 7

Electrical connection - socket

Connector: 1 x M12, angled; coding: A; Moulded body: PA; Locking: brass, nickel-plated



Connection

