


# E11143



## Connecting cable with plug

ASTGH050MSS0010H05

Article no longer available - archive entry

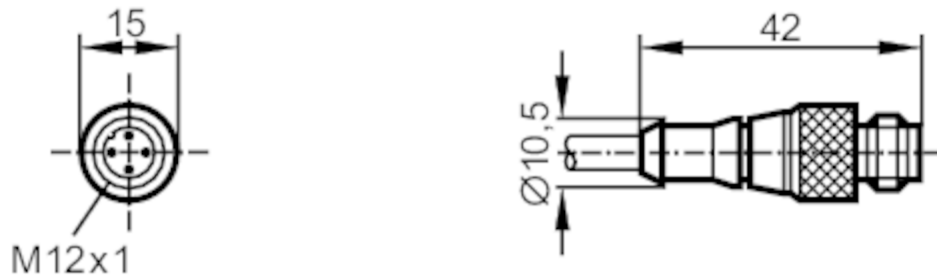

### Application

Special feature Halogen-free

### Electrical data

Operating voltage [V] < 30 AC / < 36 DC

### Operating conditions

Ambient temperature [°C] -25...90

Protection IP 67

### Mechanical data

Dimensions [mm] 15 x 15 x 42

Materials TPU

Moulded-body material TPU

Material nut brass, nickel-plated

### Remarks

Pack quantity 1 pcs.

### Electrical connection

Cable: 10 m, PUR, Halogen-free, black, Ø 5.6 mm; 5 x 0.5 mm<sup>2</sup> (16 x Ø 0.2 mm )

### Electrical connection - plug


Connector: 1 x M12, straight; Moulded body: TPU; Locking: brass, nickel-plated; Tightening torque: 0.5 Nm

# E11143



## Connecting cable with plug

ASTGH050MSS0010H05

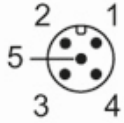

### Connection

1	BN
2	WH
3	BU
4	BK
5	GN/YE

Core colours :

BK =	black
BN =	brown
BU =	blue
GN =	green
WH =	white
YE =	yellow