


Connection cable

VDOAH043MSS0003H04STGH040MSS

Article no longer available - archive entry

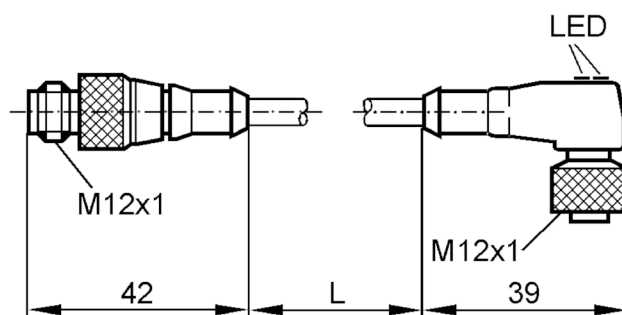

Application

Special feature

Halogen-free

Electrical data

Operating voltage

[V]

10...30 DC

Operating conditions

Ambient temperature

[°C]

-25...90

Protection

IP 67

Mechanical data

Materials

TPU

Moulded-body material

TPU

Material nut

brass, nickel-plated

Displays / operating elements

Display

switching status

2 x LED, yellow

operation

1 x LED, green

Remarks

Pack quantity

1 pcs.



Connection cable

VDOAH043MSS0003H04STGH040MSS

Electrical connection - plug


Connector: 1 x M12, straight; coding: A; Moulded body: TPU; Locking: brass, nickel-plated; Tightening torque: 0.5 Nm



Electrical connection

Cable: 3 m, PUR, Halogen-free, black, Ø 4.7 mm; 4 x 0.34 mm² (43 x Ø 0.1 mm)

Connection

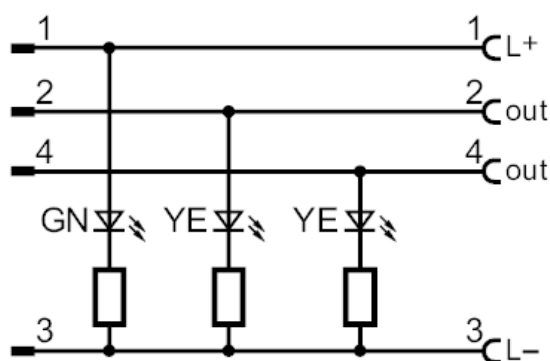

Core colours :
 BK = black
 BN = brown
 BU = blue
 WH = white

Electrical connection - socket

Connector: 1 x M12, angled; coding: A; Moulded body: TPU; Locking: brass, nickel-plated; Tightening torque: 0.5 Nm

