




Jumper cable with valve plug

VVDAB031--S0003H03STGH030MSS

Article no longer available - archive entry

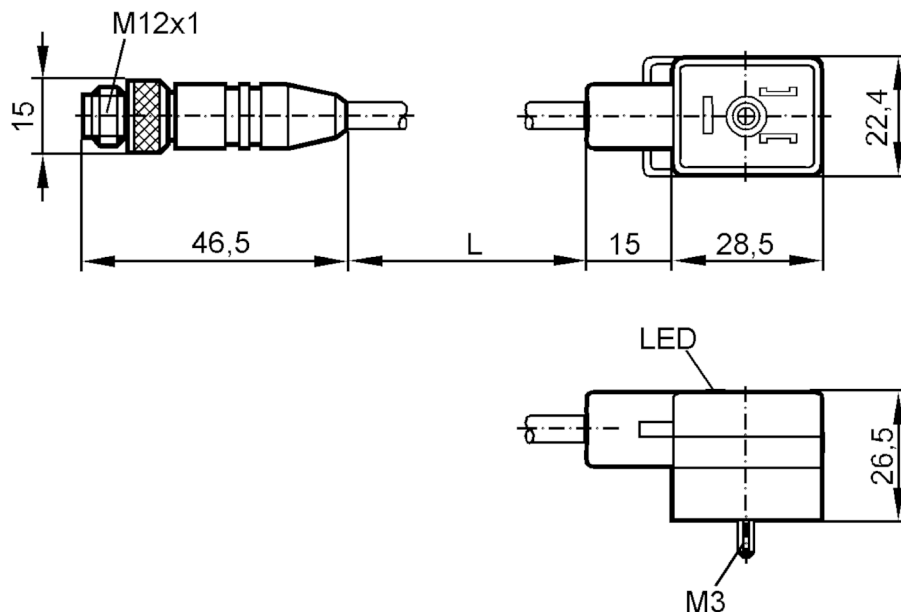

Application

Special feature

Halogen-free

Electrical data

Operating voltage

[V]

< 24 AC/DC

Overvoltage protection

yes; (VDR)

Operating conditions

Ambient temperature

[°C]

-25...90

Protection

IP 67

Mechanical data

Dimensions

[mm]

15 x 15 x 46.5

Materials

TPU

Moulded-body material

TPU

Material nut

brass, nickel-plated

Displays / operating elements

Display

switching status

1 x LED, yellow

Accessories

Items supplied

screw

panel for labelling

Remarks

Pack quantity

1 pcs.




Jumper cable with valve plug

VVDAB031--S0003H03STGH030MSS

Electrical connection - plug

 
Connector: 1 x M12, straight; coding: A; Moulded body: TPU; Locking: brass, nickel-plated



Electrical connection

Cable: 3 m, PUR, Halogen-free; 3 x 0.5 mm²

Connection

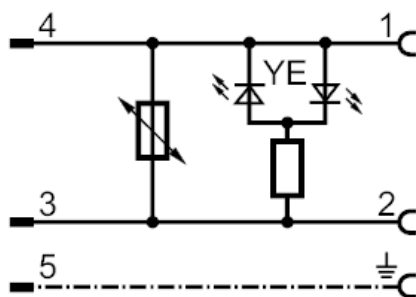

Electrical connection - socket

Connector: 1 x valve type B DIN, angled; Moulded body: TPU; Locking: brass, nickel-plated

