


# E12653



## Connection cable

VDOGX050MSS0001H05STGH005MSS

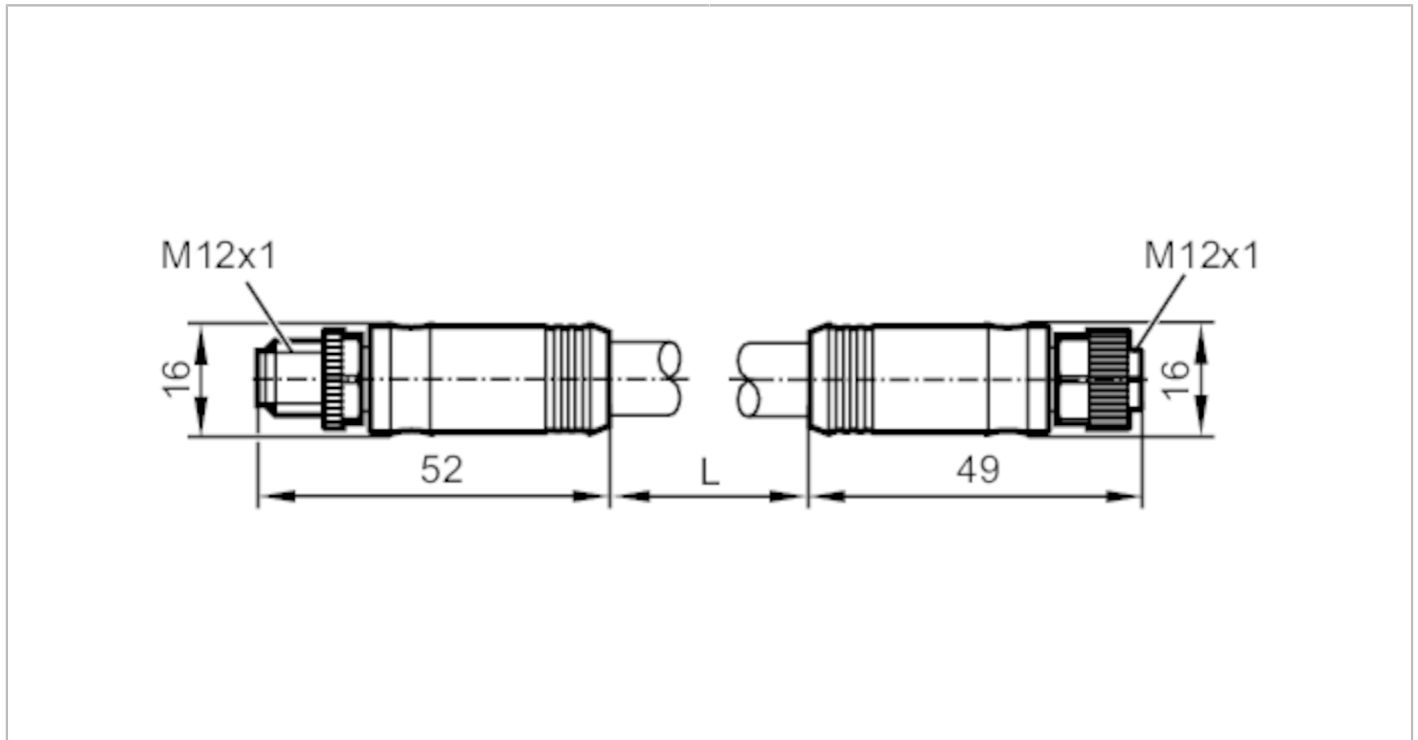

Application	
Special feature	Gold-plated contacts
Design	power cable, L-coded
Electrical data	
Operating voltage [V]	64 DC
Max. current load total [A]	16
Operating conditions	
Ambient temperature [°C]	-40...90
Protection	IP 67
Mechanical data	
Weight [g]	230.3
Materials	PP
Moulded-body material	TPE
Material nut	brass, nickel-plated
Remarks	
Pack quantity	1 pcs.
Electrical connection	
Cable: 1.0 m, PUR, black, Ø 11.3 mm; 5 x 2.5 mm <sup>2</sup>	
Electrical connection - plug	
Connector: 1 x M12, straight; coding: L; Moulded body: TPE; Locking: brass, nickel-plated; Contacts: gold-plated	

# E12653




## Connection cable

VDOGX050MSS0001H05STGH005MSS



### Electrical connection - 2

#### Connection

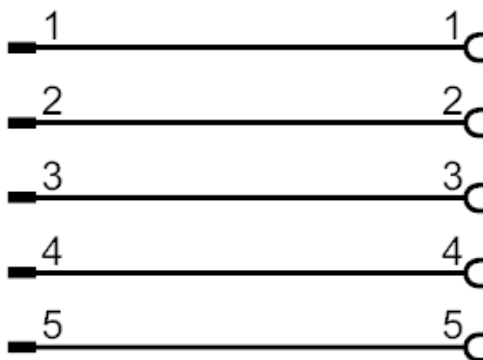

### Electrical connection - socket

Connector: 1 x M12, straight; coding: L; Moulded body: TPE; Locking: brass, nickel-plated; Contacts: gold-plated

