


E18181




Connection cable

VDOAH040VAS01.5E03STGH040VAS

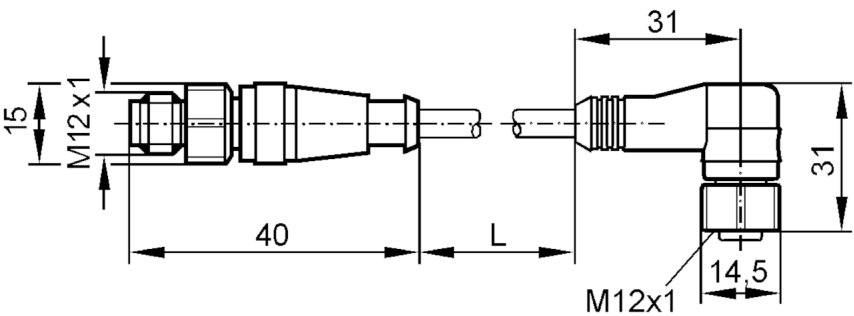

Application	
Special feature	Gold-plated contacts
Electrical data	
Operating voltage [V]	< 300 AC/DC
Operating conditions	
Ambient temperature [°C]	-20...105
Protection	IP 68
Mechanical data	
Weight [g]	63.503
Materials	TPE
Moulded-body material	TPE
Material nut	stainless steel (316Ti/1.4571)
Remarks	
Pack quantity	1 pcs.
Electrical connection - plug	

Connector: 1 x M12, straight; coding: A; Moulded body: TPE; Locking: stainless steel (316Ti/1.4571); Contacts: gold-plated

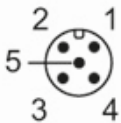

E18181



Connection cable

VDOAH040VAS01.5E03STGH040VAS

Electrical connection

Cable: 1.5 m, PVC, grey; 3 x 0.34 mm² / AWG 22

Connection



Electrical connection - socket

Connector: 1 x M12, angled; coding: A; Moulded body: TPE; Locking: stainless steel (316Ti/1.4571); Contacts: gold-plated

