


# E19939


## Splitter box

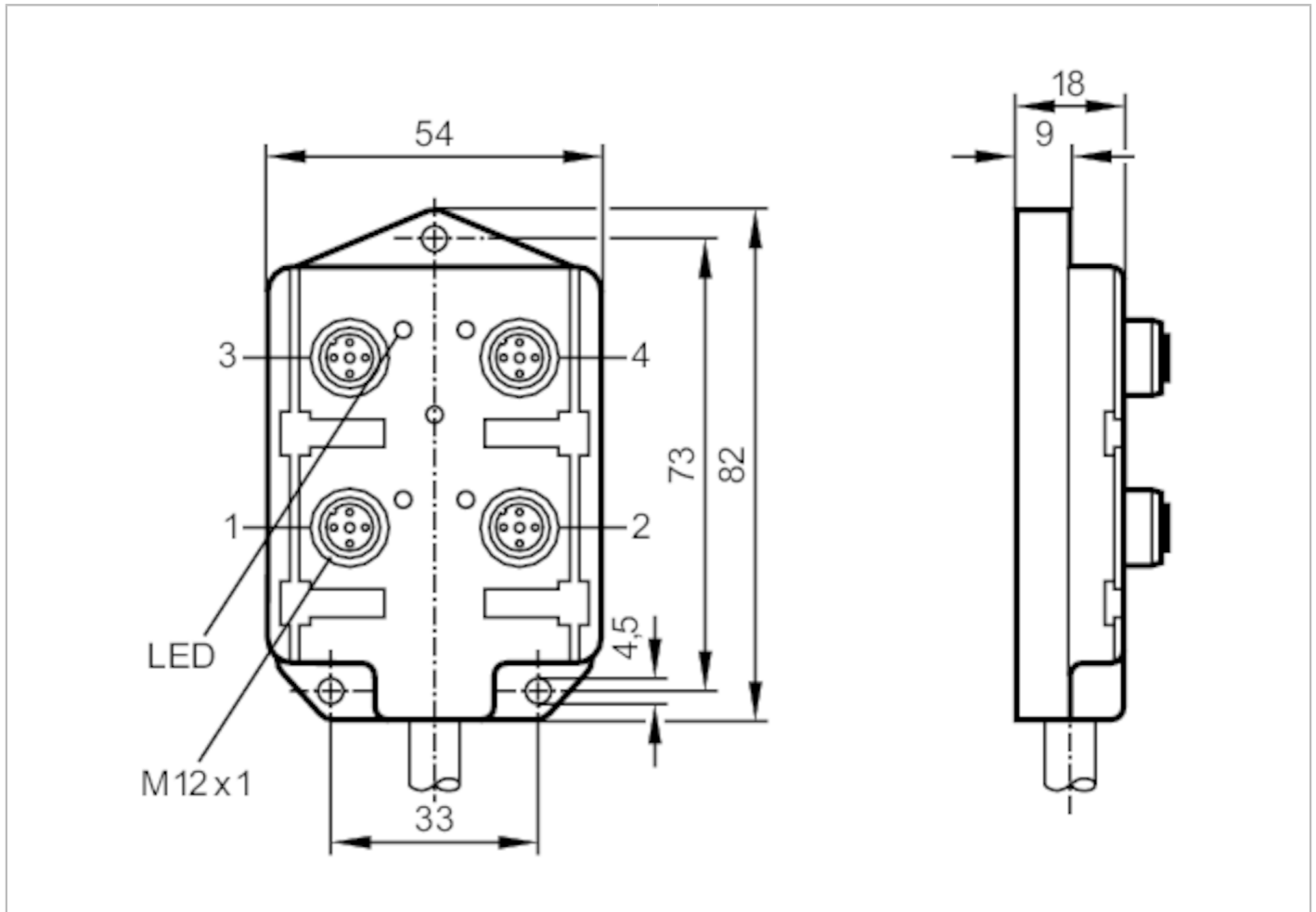

Electrical data		
Operating voltage	[V]	10...110 AC/DC
Max. current load per module/slot	[A]	4
Max. current load total	[A]	12
Operating conditions		
Ambient temperature	[°C]	-15...90
Protection		IP 67
Mechanical data		
Dimensions	[mm]	18 x 54 x 82
Number of ports splitter box		4
Remarks		
Pack quantity		1 pcs.
Electrical connection		
Cable: 5 m, PUR / PVC; 4 x 0.34 mm <sup>2</sup> + 3 x 0.75 mm <sup>2</sup>		
Electrical connection - slot		
Connector: 4 x M12		

# E19939

## Splitter box

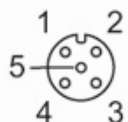

### Connection

<u>BN</u>	<u>1 (1...4)</u>	<u>C</u>
<u>BU</u>	<u>3 (1...4)</u>	<u>C</u>
<u>GN/YE</u>	<u>5 (1...4)</u>	<u>C</u>
<u>WH</u>	<u>4 (1)</u>	<u>C</u>
<u>GN</u>	<u>4 (2)</u>	<u>C</u>
<u>YE</u>	<u>4 (3)</u>	<u>C</u>
<u>GY</u>	<u>4 (4)</u>	<u>C</u>

#### Core colours :

BN =	brown
BU =	blue
GN =	green
GN/YE =	green/yellow
GY =	grey
WH =	white
YE =	yellow