




Adapter plug

ADAPTER PLUG US-100

Article no longer available - archive entry

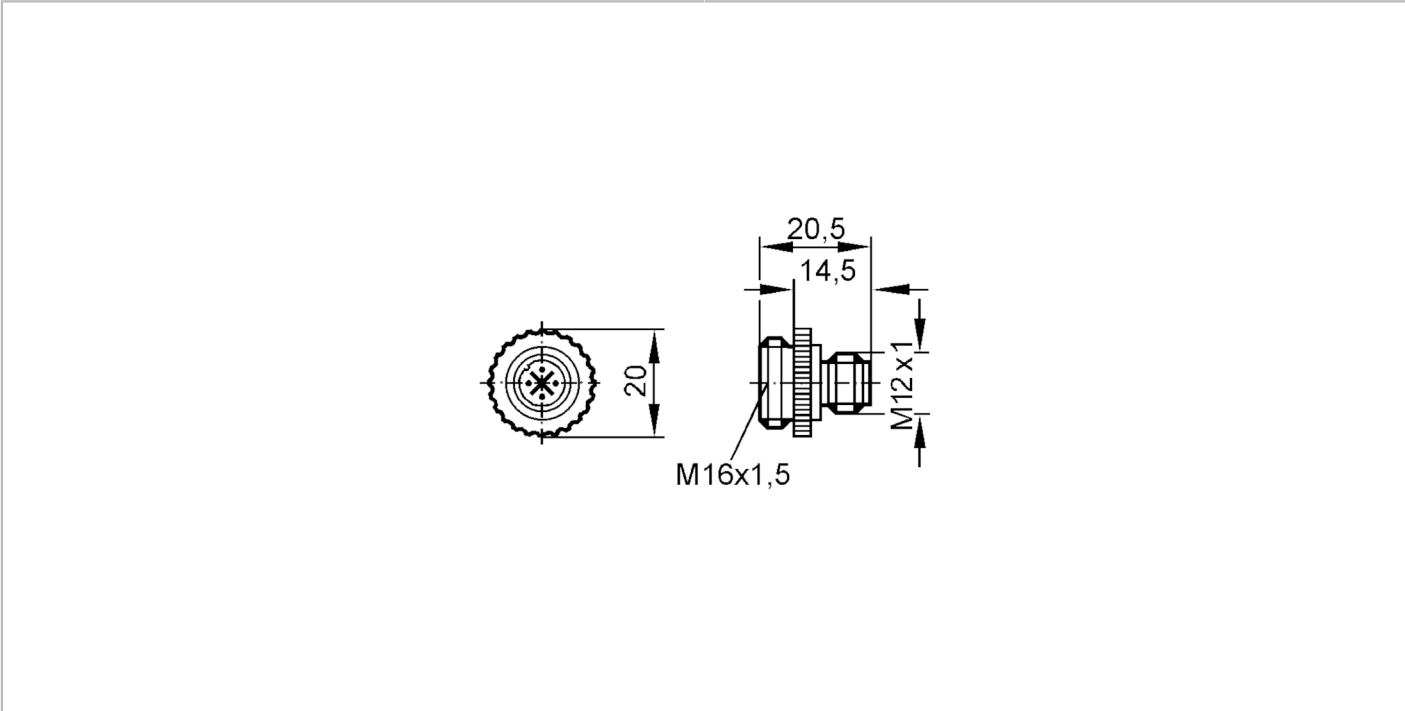

Electrical data

Operating voltage	[V]	< 250 AC / < 300 DC
-------------------	-----	---------------------

Operating conditions

Ambient temperature	[°C]	-40...85
Protection		IP 67

Mechanical data

Weight	[g]	0.013
Mounting thread		M16
Materials		brass nickel-plated
Moulded-body material		brass, nickel-plated

Remarks


Pack quantity		1 pcs.
---------------	--	--------

Electrical connection

Cable: 0.065 m, PVC; 4 x 0.34 mm ²

Electrical connection - plug

Connector: 1 x M12; coding: A; Moulded body: brass, nickel-plated

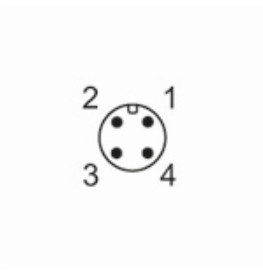

E20685



Adapter plug

ADAPTER PLUG US-100

Connection

1	BN
2	WH
3	BU
4	BK

	Core colours :
BK =	black
BN =	brown
BU =	blue
WH =	white