


Fibre optic diffuse reflection sensor

FT-00-A-A-R4/2,5M

Article no longer available - archive entry

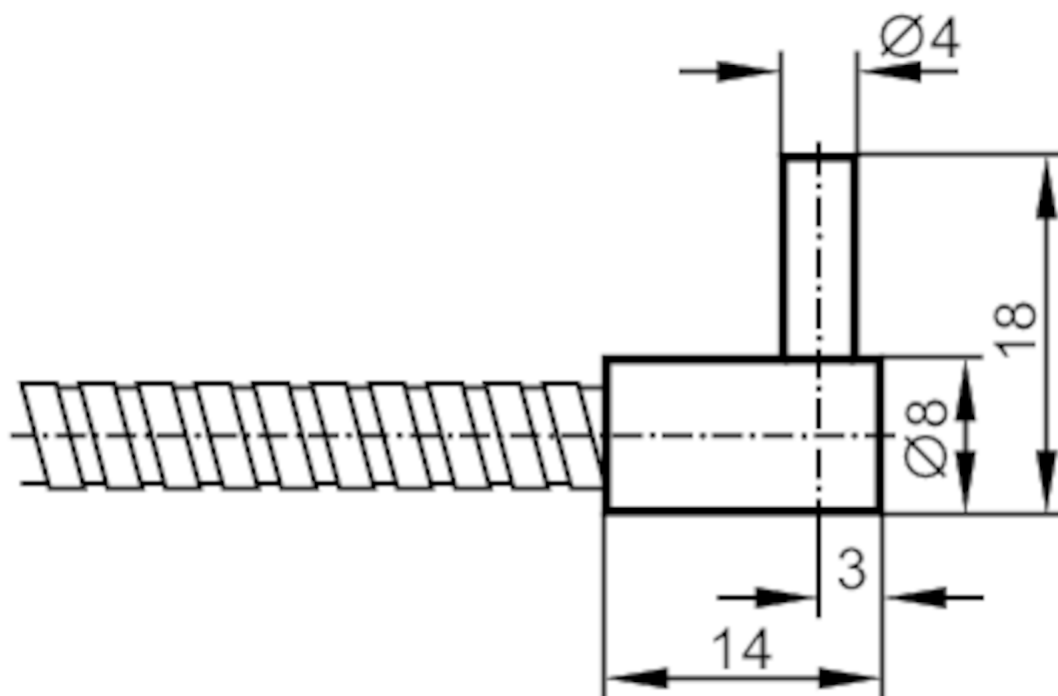

Application

Function principle

Diffuse reflection sensor

Detection zone

Range with fibre optic amplifier type

OKF; OUF

OKF

Range fibre optics

[mm]

28

OUF

Range fibre optics

[mm]

28

Operating conditions

Ambient temperature

[°C]

-40...290

Mechanical data

Version of sensing head

angled

Sensing head diameter

[mm]

4

Sensing head length

[mm]

10

Total length

[mm]

2500

Min. bending radius

[mm]

20

Materials

Adapter: ABS

Fibre material

glass

E20355



Fibre optic diffuse reflection sensor

FT-00-A-A-R4/2,5M

Fibre head material	aluminium
Fibre sheath material	aluminium
Remarks	
Pack quantity	1 pcs.