


Sound tube

SOUND TUBE M30

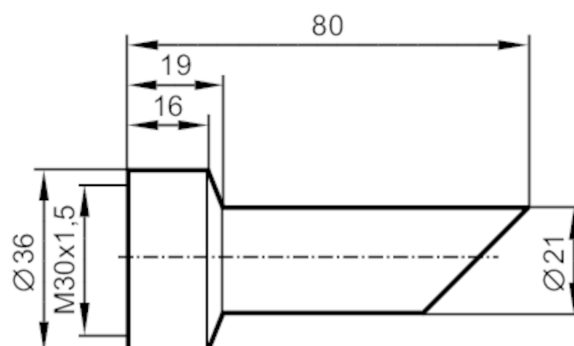

Application

Design for all ifm ultrasonic sensors with M30 thread and maximum range of 3.5 m


Mechanical data

Weight	[g]	24.5
Materials		POM
Sealing		Gasket


Remarks

Pack quantity 1 pcs.


Diagrams and graphs

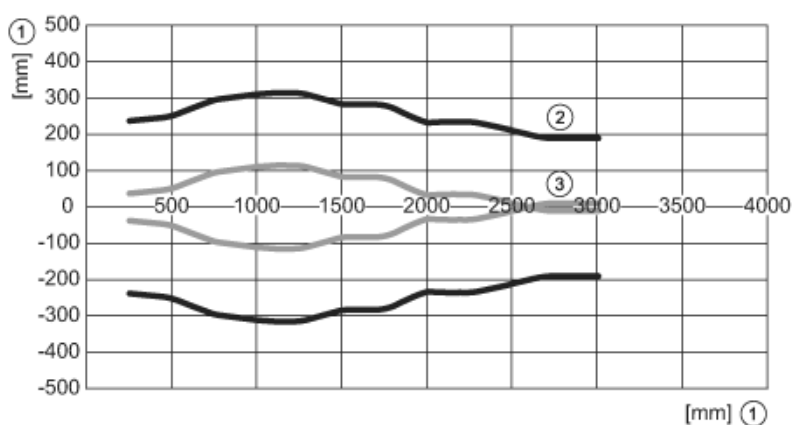


standard sound beam with sound tube

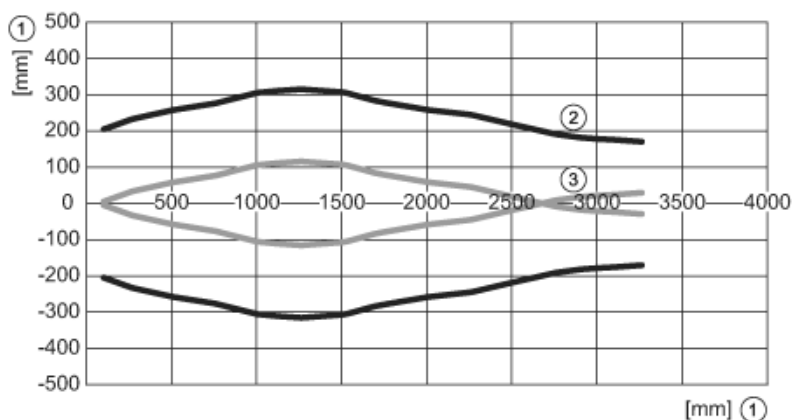

medium sound beam with sound tube

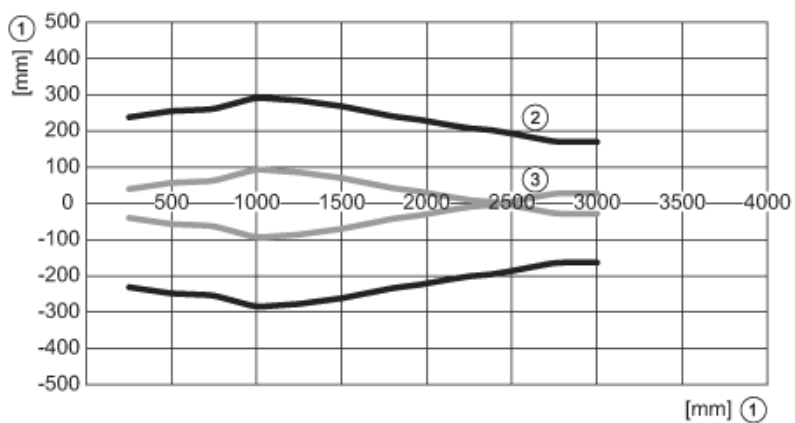

narrow sound beam with sound tube

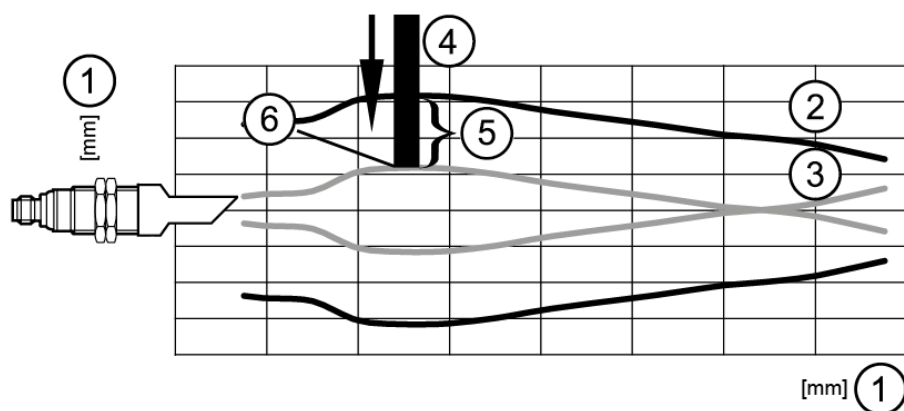

- 1 distance
- 2 Detection zone
- 3 switch-on/switch-off graph
- 4 Target
- 5 50% of the target in the detection zone
- 6 switch point