


## Mounting adapter for process sensors

ADAPT IFM-BREWERY D=48

Article no longer available - archive entry

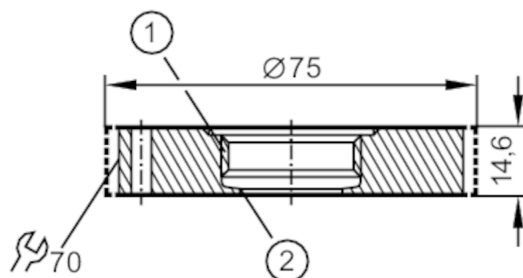

- 1 Aseptoflex thread  
2 Aseptoflex sealing edge

## Application

|                 |       |    |
|-----------------|-------|----|
| Pressure rating | [bar] | 10 |
|-----------------|-------|----|

## Mechanical data

|                                                   |                                 |
|---------------------------------------------------|---------------------------------|
| Materials                                         | stainless steel (1.4404 / 316L) |
| Sensor connection                                 | Aseptoflex                      |
| Process connection                                | flange                          |
| Surface characteristics Ra/Rz of the wetted parts | 0.4 / 4                         |
| Hygienic equipment class to DIN 11866             | H4                              |

## Remarks

|               |        |
|---------------|--------|
| Pack quantity | 1 pcs. |
|---------------|--------|