


E70047



Connection cable

VDOAH040MSS01,5A04STGH040MSS

Article no longer available - archive entry

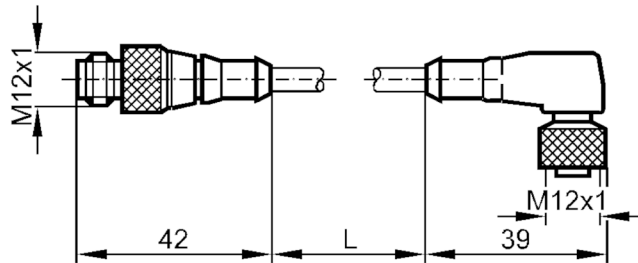

Electrical data

Operating voltage [V] 10...30 DC

Operating conditions

Ambient temperature [°C] -25...90

Protection IP 67

Mechanical data

Materials TPU

Moulded-body material TPU

Material nut brass, nickel-plated

Remarks

Pack quantity 1 pcs.

Electrical connection - plug

Connector: 1 x M12, straight; Moulded body: TPU; Locking: brass, nickel-plated; Tightening torque: 0.5 Nm



E70047




Connection cable

VDOAH040MSS01,5A04STGH040MSS

Electrical connection

Cable: 1.5 m, PUR / PVC; 4 x 0.25 mm²

Connection

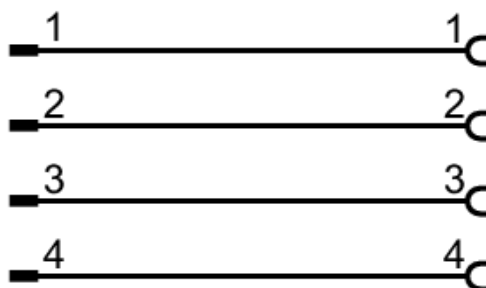

Electrical connection - socket

Connector: 1 x M12, angled; Moulded body: TPU; Locking: brass, nickel-plated; Tightening torque: 0.5 Nm

