


Jumper cable with valve plug

VVDAB031--S00,6A03STAH030VAS

Article no longer available - archive entry

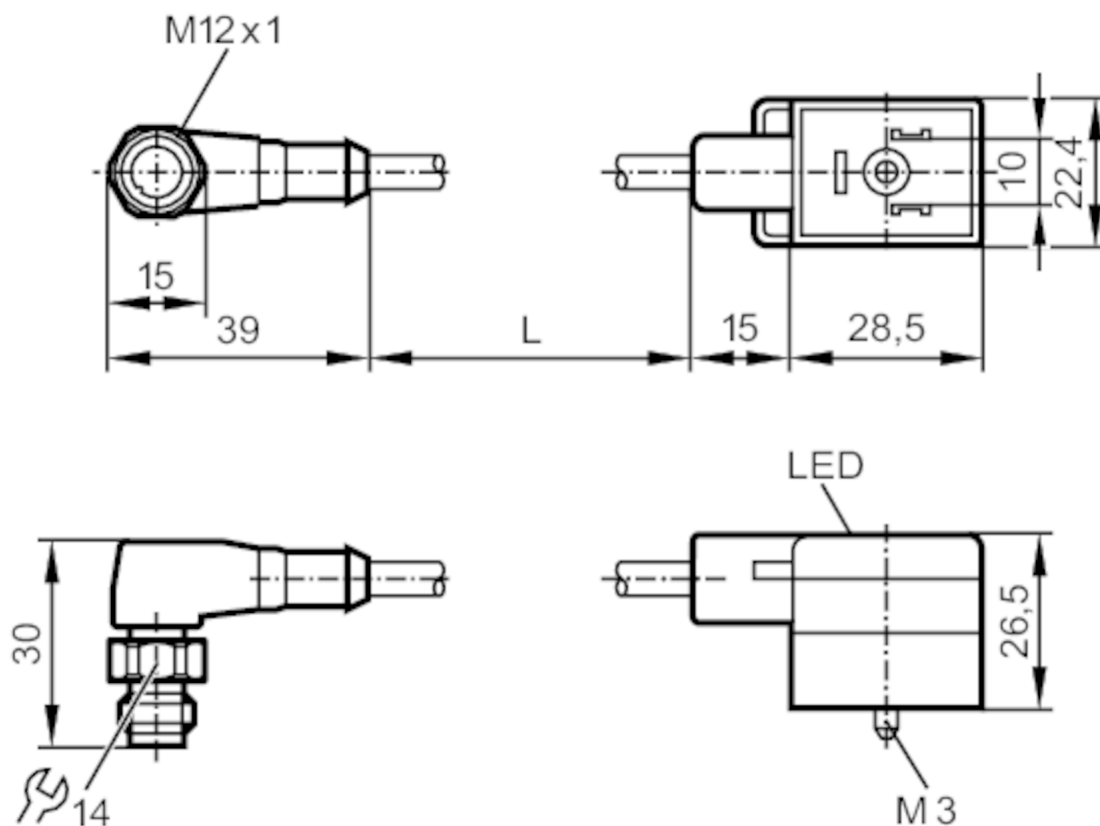

Application

Special feature

Halogen-free

Electrical data

Operating voltage

[V]

< 24 AC/DC

Operating conditions

Ambient temperature

[°C]

-25...90

Protection

IP 67

Mechanical data

Dimensions

[mm]

30 x 15 x 39

Materials

PUR

Moulded-body material

PUR

Material nut

stainless steel (316L/1.4404)

Displays / operating elements

Display

switching status

1 x LED, yellow

Accessories

Items supplied

screw

panel for labelling

E70145



Jumper cable with valve plug

VVDAB031--S00,6A03STAH030VAS

 
Remarks

Pack quantity

1 pcs.

Electrical connection - plug


Connector: 1 x M12, angled; coding: A; Moulded body: PUR; Locking: stainless steel (316L/1.4404)



Electrical connection

Cable: 0.6 m, PUR, Halogen-free, black, Ø 5.5 mm; 3 x 0.5 mm² (16 x Ø 0.2 mm)

Connection

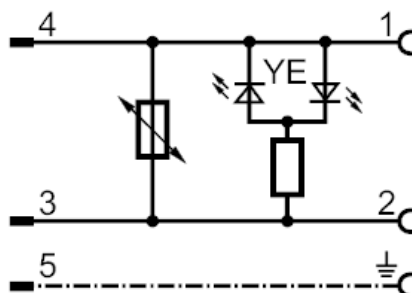

Electrical connection - socket

Connector: 1 x valve type B DIN, angled; Moulded body: PUR; Locking: stainless steel (316L/1.4404)

