




Connection cable

VDOAH030VAS0001E03STGH030VAS

Article no longer available - archive entry

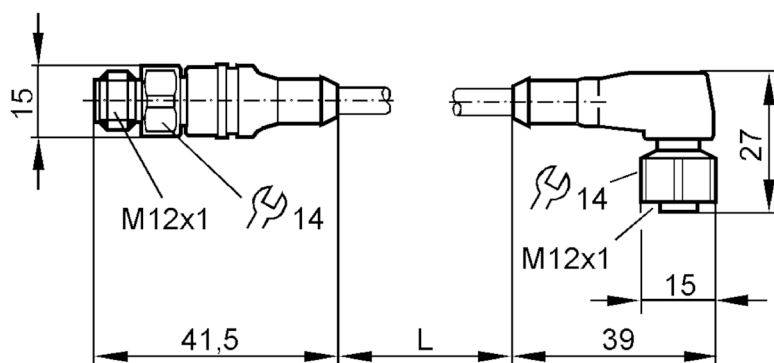

Electrical data

Operating voltage	[V]	< 250 AC / < 300 DC
-------------------	-----	---------------------

Operating conditions

Ambient temperature	[°C]	-25...100
---------------------	------	-----------

Protection	IP 67
------------	-------

Mechanical data

Dimensions	[mm]	15 x 15 x 41.5
------------	------	----------------

Materials	PVC
-----------	-----

Moulded-body material	PVC
-----------------------	-----

Material nut	stainless steel (316L/1.4404)
--------------	-------------------------------

Remarks

Pack quantity	1 pcs.
---------------	--------

Electrical connection - plug

Connector: 1 x M12, straight; coding: A; Moulded body: PVC; Locking: stainless steel (316L/1.4404)



E70202




Connection cable

VDOAH030VAS0001E03STGH030VAS

Electrical connection

Cable: 1 m, PVC; 3 x 0.34 mm² (42 x Ø 0.1 mm)

Connection

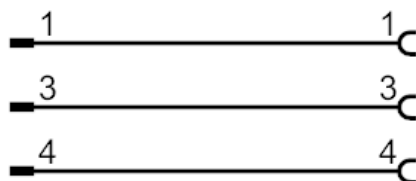

Electrical connection - socket

Connector: 1 x M12, angled; coding: A; Moulded body: PVC; Locking: stainless steel (316L/1.4404)

