



Connecting cable with socket

ADOGH040MSN0010H04/1G/1D



| Application                 |                                                                                 |
|-----------------------------|---------------------------------------------------------------------------------|
| Special feature             | Free from silicone; Halogen-free; Gold-plated contacts                          |
| Free from silicone          | yes                                                                             |
| Compatible with paint       | yes                                                                             |
| Electrical data             |                                                                                 |
| Operating voltage [V]       | < 30 DC                                                                         |
| Protection class            | II                                                                              |
| Max. input power [mW]       | group II: 1000; group III: 1000                                                 |
| Max. current load total [A] | 1                                                                               |
| Operating conditions        |                                                                                 |
| Ambient temperature [°C]    | -25...85                                                                        |
| Note on ambient temperature | for use in hazardous areas: ambient temperature in accordance with unit marking |
| Protection                  | IP 67; (when used outside the hazardous area: IP 68 / IP 69K)                   |
| Tests / approvals           |                                                                                 |
| Approval                    | BVS 11 ATEX E 009 X; IECEx BVS 11.0002 X                                        |
| ATEX marking                | Ex II 1G Ex ia IIB T6 Ga Ta: -25...75°C                                         |
|                             | Ex II 2G Ex ia IIC T6 Gb Ta: -25...75°C                                         |
|                             | Ex II 1G Ex ia IIB T5 Ga Ta: -25...85°C                                         |
|                             | Ex II 2G Ex ia IIC T5 Gb Ta: -25...85°C                                         |
|                             | Ex II 1D Ex ia IIB T200 85°C Da Ta: -25...75°C                                  |
|                             | Ex II 1D Ex ia IIB T200 95°C Da Ta: -25...85°C                                  |
|                             | Ex II 1D Ex ia IIC T200 70°C Da Ta: -20...60°C                                  |

# ENC03A




## Connecting cable with socket

ADOGH040MSN0010H04/1G/1D

| Safety classification     |                                                                                             |                  |
|---------------------------|---------------------------------------------------------------------------------------------|------------------|
| Max. internal capacitance | [nF]                                                                                        | 1                |
| Max. internal inductance  | [μH]                                                                                        | 20               |
| Mechanical data           |                                                                                             |                  |
| Weight                    | [g]                                                                                         | 351.7            |
| Dimensions                | [mm]                                                                                        | 15.5 x 15.5 x 45 |
| Materials                 | housing: TPU orange; Sealing: FKM                                                           |                  |
| Material nut              | brass, nickel-plated                                                                        |                  |
| Remarks                   |                                                                                             |                  |
| Remarks                   | Special conditions for safe operation apply for use in hazardous areas.                     |                  |
|                           | Observe the corresponding notes in the operating instructions (Ex protection related part). |                  |
| Pack quantity             | 1 pcs.                                                                                      |                  |

| Electrical connection                                                         |  |
|-------------------------------------------------------------------------------|--|
| Cable: 10 m, PUR, Halogen-free, blue, Ø 4.9 mm; 4 x 0.34 mm² (42 x Ø 0.1 mm ) |  |

| Electrical connection - socket                                                                                                 |  |
|--------------------------------------------------------------------------------------------------------------------------------|--|
| Connector: 1 x M12, straight; coding: A; Locking: brass, nickel-plated; Contacts: gold-plated; Tightening torque: 0.6...1.5 Nm |  |

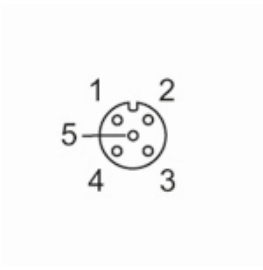

| Connection                                                                                                                                                                  |  |
|-----------------------------------------------------------------------------------------------------------------------------------------------------------------------------|--|
| <div><div><div>1</div><div>2</div><div>3</div><div>4</div><div>5</div></div><div><div>BN</div><div>WH</div><div>BU</div><div>BK</div></div></div>                           |  |
| <div><div>BK =</div><div>BN =</div><div>BU =</div><div>WH =</div></div> <div><div>Core colours :</div><div>black</div><div>brown</div><div>blue</div><div>white</div></div> |  |