


# EVT168



## Connection cable

VDOAF030VAS0001E03STAF030VAS

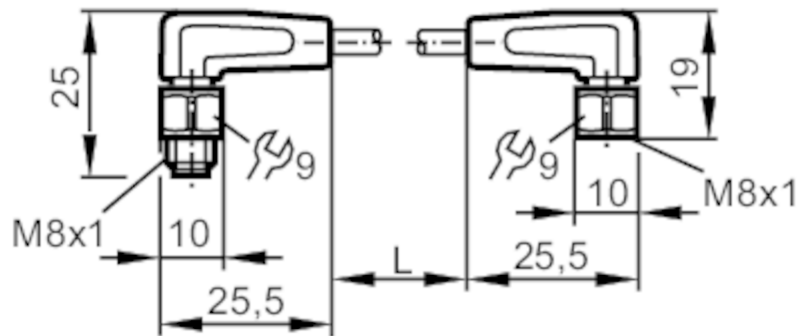

### Application

|                    |  |
|--------------------|--|
| Special feature    | Free from silicone; Gold-plated contacts; Drag chain suitability |
| Application        | hygienic and wet areas in the food industry                      |
| Free from silicone | yes  |

### Electrical data

|                         |     |                   |
|-------------------------|-----|-------------------|
| Operating voltage       | [V] | < 50 AC / < 60 DC |
| Protection class        |     | III               |
| Max. current load total | [A] | 3                 |

### Operating conditions

|                                      |      |                             |
|--------------------------------------|------|-----------------------------|
| Ambient temperature                  | [°C] | -25...80                    |
| Note on ambient temperature          |      | cULus: ...50                |
| Ambient temperature (moving)         | [°C] | 5...80                      |
| Note on ambient temperature (moving) |      | cULus: ...50                |
| Protection                           |      | IP 65; IP 67; IP 68; IP 69K |

### Mechanical data

|                        |      |                                    |
|------------------------|------|------------------------------------|
| Weight                 | [g]  | 51.2                               |
| Dimensions             | [mm] | 25 x 10 x 25.5                     |
| Materials              |      | housing: PVC orange; Sealing: EPDM |
| Material nut           |      | stainless steel (1.4404 / 316L)    |
| Drag chain suitability |      | yes                                |



## Connection cable

VDOAF030VAS0001E03STAF030VAS

|                        |                                 |  |
|------------------------|---------------------------------|--|
| Drag chain suitability | bending radius for flexible use | min. 10 x cable diameter   |
|                        | travel speed                    | max. 3.3 m/s for a horizontal travel length of 5 m and max. acceleration of 5 m/s <sup>2</sup> |
|                        | bending cycles                  | > 1 Mio.   |
|                        | torsional strain                | ± 180 °/m  |

### Remarks

|               |        |
|---------------|--------|
| Pack quantity | 1 pcs. |
|---------------|--------|

### Electrical connection - plug


Connector: 1 x M8, angled; coding: A; Locking: stainless steel (1.4404 / 316L); Contacts: gold-plated; Tightening torque: 0.3...0.5 Nm



### Electrical connection

Cable: 1 m, PVC, orange, Ø 4.9 mm; 3 x 0.34 mm<sup>2</sup> (42 x Ø 0.1 mm)

### Connection

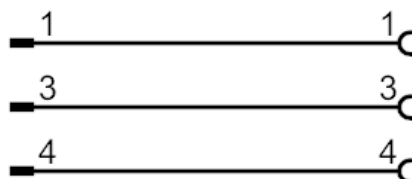

### Electrical connection - socket

Connector: 1 x M8, angled; coding: A; Locking: stainless steel (1.4404 / 316L); Contacts: gold-plated; Tightening torque: 0.3...0.5 Nm

