


# OR0016



## Diffuse reflection sensor

ORT-V

Article no longer available - archive entry

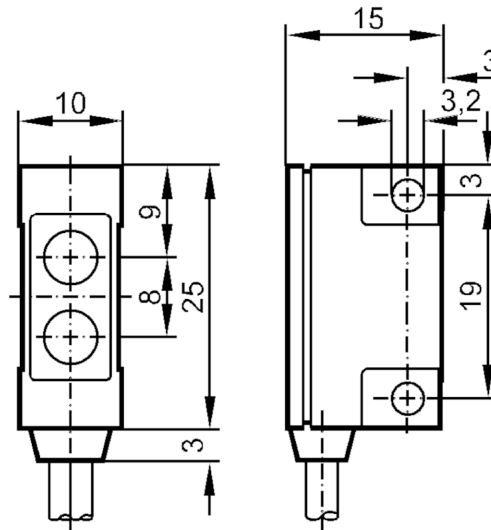

receiver in upper lens  
transmitter in lower lens

Product characteristics	
Housing	rectangular
Dimensions [mm]	25 x 10 x 15
Application	
Function principle	Diffuse reflection sensor
Electrical data	
Connection to switching amplifiers	yes
Switching amplifiers	Connection to switching amplifiers OV5012, OV0010
Outputs	
Short-circuit protection	no
Overload protection	no
Detection zone	
Range [mm]	< 300; (white paper 200 x 200 mm)
Operating conditions	
Protection	IP 67
Mechanical data	
Housing	rectangular
Dimensions [mm]	25 x 10 x 15
Materials	PPO modified
Accessories	
Accessories (supplied)	Angle bracket: 1 x, E20212

# OR0016



## Diffuse reflection sensor

ORT-V


### Remarks

Pack quantity \_\_\_\_\_ 1 pcs.

### Electrical connection

Cable: 2 m; 1 x 0.14 mm<sup>2</sup>

### Connection

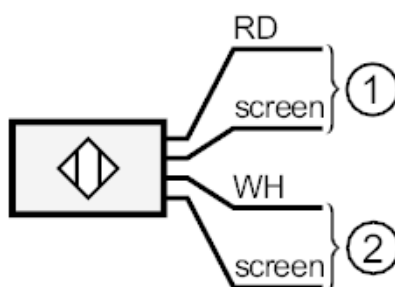

1 = transmitter

2 = receiver

Core colours :

RD = red

WH = white

screen = screen

Article no longer available - archive entry