


E20138



Fibre optic diffuse reflection sensor

FT-00-A-A-E3/2M

Article no longer available - archive entry

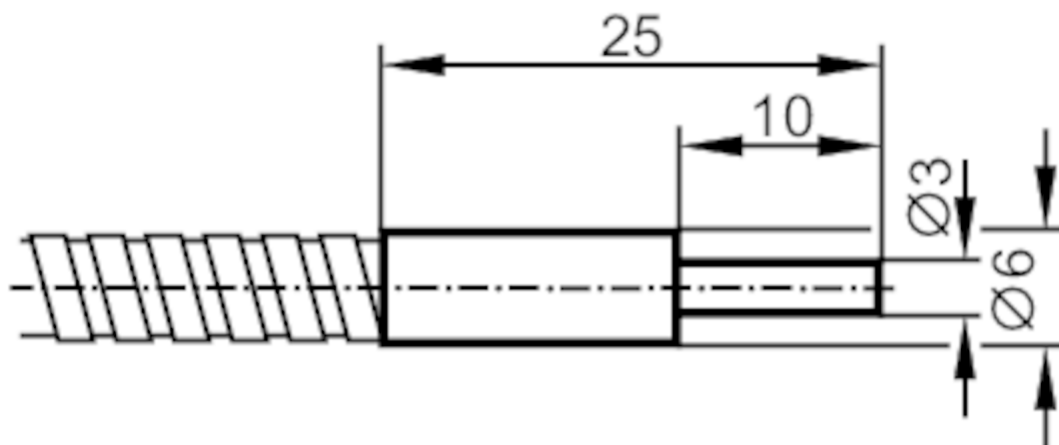

Application

Function principle Diffuse reflection sensor

Detection zone

Range with fibre optic amplifier type OKF; OUF

OKF

Range fibre optics [mm] 32

OUF

Range fibre optics [mm] 32

Operating conditions

Ambient temperature [°C] -40...290

E20138



Fibre optic diffuse reflection sensor

FT-00-A-A-E3/2M

Mechanical data	
Version of sensing head	straight
Sensing head diameter [mm]	3
Sensing head length [mm]	10
Total length [mm]	2000
Min. bending radius [mm]	20
Materials	Adapter: ABS
Fibre material	glass
Fibre head material	aluminium
Fibre sheath material	aluminium
Remarks	
Pack quantity	1 pcs.

Article no longer available - archive entry