

Technical drawing of the LED module showing top and side views with dimensions.

Top View Dimensions:

- Overall width: 54
- Overall height: 100
- Distance between LED centers (vertical): 73
- Distance between LED centers (horizontal): 33
- LED diameter: 4,5
- Mounting hole diameter: M12x1

Side View Dimensions:

- Module thickness: 18

Caractéristique spécifique	Sans silicone; Sans halogène; contacts dorés
Sans silicone	oui

Tension d'alimentation	[V]	10...30 DC
Classe de protection		II
Courant de sortie par module / emplacement	[A]	4
Courant de sortie total	[A]	12

Température ambiante [°C]	-15...80
Indice de protection	IP 67

Dimensions	[mm]	18 x 54 x 100
Matières		TPU
Matière du corps		TPU
Nombre d'emplacements répartiteur		6

E11570



Répartiteur

ZDO6H057MSS00,5H09

Type connecteur	M12
-----------------	-----

Afficheurs / éléments de service

Indication	état de commutation	6 x LED, jaune
	fonctionnement	1 x LED, vert

Remarques


Unité d'emballage	1 pièces
-------------------	----------

Raccordement électrique

Câble: 0,5 m, PUR, Sans halogène, noir, Ø 9 mm; 6 x 0,34 mm² + 3 x 0,75 mm²

Raccordement électrique - emplacement

Connecteur: 6 x M12; codage: A; Corps: TPU; Contacts: doré; Couple de serrage: 0,5 Nm

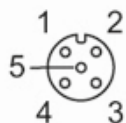


E11570



Répartiteur

ZDO6H057MSS00,5H09

Raccordement

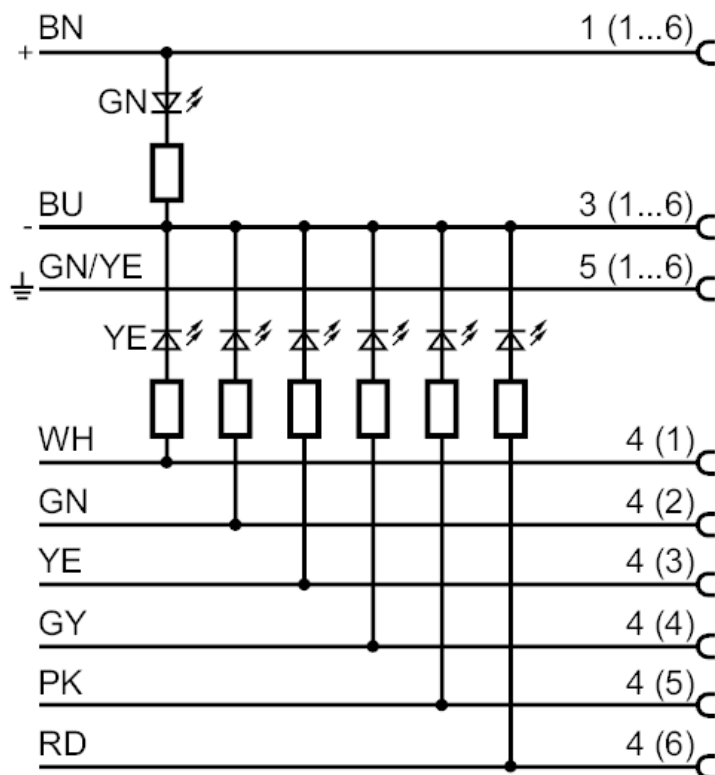

Couleurs des fils conducteurs :

BN =	brun
BU =	bleu
GN =	vert
GN/YE =	vert / jaune
GY =	gris
PK =	rose
RD =	rouge
WH =	blanc
YE =	jaune