


E3R100



Verbindingskabel

HFM Y CABLE 2 X S/S/M S/D/M A 2,0M

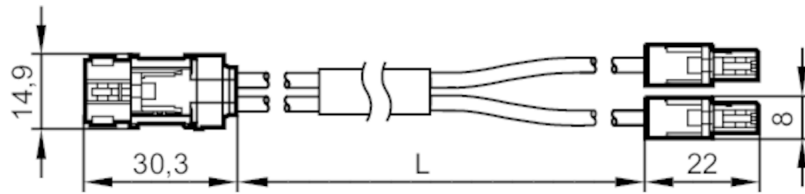

Elektrische eigenschappen

Voedingsspanning	[V]	< 50 AC / < 60 DC
Beschermklasse		III
Demping	[dB/m]	1,6
Inwendige weerstand (Ri)	[Ω]	50; (± 3 %)

Omgevingsvariabelen

Omgevingstemperatuur	[°C]	-10...60
Omgevingstemperatuur (bewegend)	[°C]	-10...60
Beschermklasse		IP 54

Mechanische eigenschappen

Gewicht	[g]	91,62
Minimale buigradius	[mm]	16,5; (enkel; 15 x 3,3 mm min. 10 x kabeldiameter)
Materialen		behuizing: : PBT-GF20

Opmerkingen

Verpakkingseenheid		1 stuk
--------------------	--	--------

Elektrische aansluiting - 2D/3D-camera

Connector: 1 x HFM-Dual, recht

Elektrische aansluiting

Kabel: 2 m, zwart, Ø 3,3 mm

Elektrische aansluiting - Video Processing Unit

Connector: 2 x HFM-Single, recht