

# E10662




## Connecting cable with socket

ADOGH040VAS0005E04

Article no longer available - archive entry

replaced by: EVT001

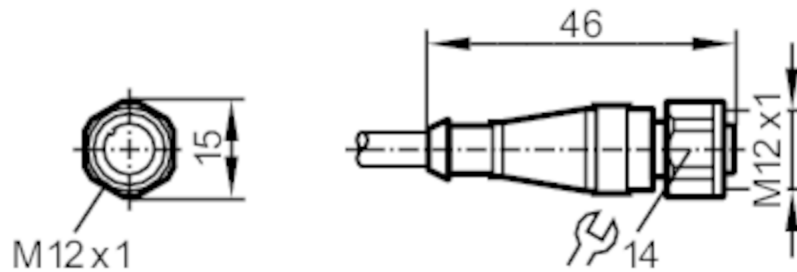

Application	
Special feature	Free from silicone; Gold-plated contacts
Free from silicone	yes
Electrical data	
Operating voltage [V]	< 250 AC / < 300 DC
Max. current load total [A]	4
Operating conditions	
Ambient temperature [°C]	-25...100
Protection	IP 68; IP 69K
Mechanical data	
Dimensions [mm]	15 x 15 x 46
Materials	PVC
Material nut	stainless steel (1.4404 / 316L)
Remarks	
Pack quantity	1 pcs.
Electrical connection	
Cable: 5 m, PVC, orange, Ø 5.3 mm; 4 x 0.34 mm <sup>2</sup> (42 x Ø 0.1 mm )	
Electrical connection - socket	
Connector: 1 x M12, straight; Moulded body: PVC; Locking: stainless steel (1.4404 / 316L); Contacts: gold-plated; Tightening torque: 0.7...0.9 Nm	

# E10662




## Connecting cable with socket

ADOGH040VAS0005E04



### Connection

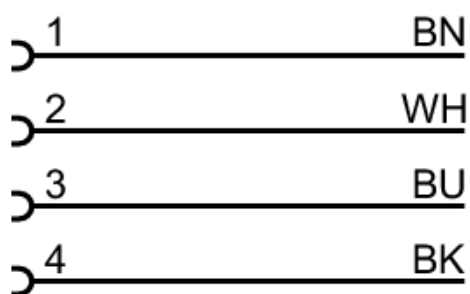

Core colours :

BK = black  
BN = brown  
BU = blue  
WH = white

Article no longer available - archive entry

replaced by: EVT001