


E18000



Connecting cable with socket

ADOGH040MKS0005X04

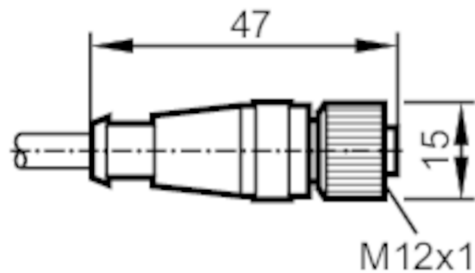

Electrical data

Operating voltage [V] < 300 AC/DC

Operating conditions

Ambient temperature [°C] -45...105

Protection IP 68

Mechanical data

Weight [g] 361.966

Dimensions [mm] 15 x 15 x 47

Materials TPE

Material nut zinc, epoxy coated

Remarks

 
Pack quantity 1 pcs.

Electrical connection

Cable: 5 m, TPE-S, black; 4 x 0.75 mm² / AWG 18

Electrical connection - socket

Connector: 1 x M12, straight; Moulded body: TPE; Locking: zinc, epoxy coated; Contacts: gold-plated




E18000



Connecting cable with socket

ADOGH040MKS0005X04

Connection

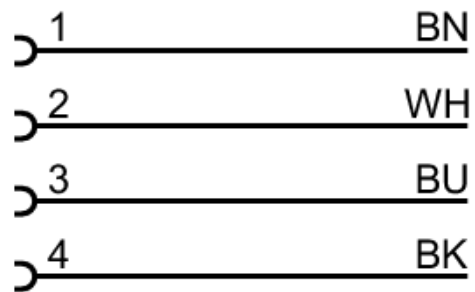

Core colours :

BK =	black
BN =	brown
BU =	blue
WH =	white