


E18267



CAN bus terminating resistor

M12 PASSTHROUGH W/RESISTOR

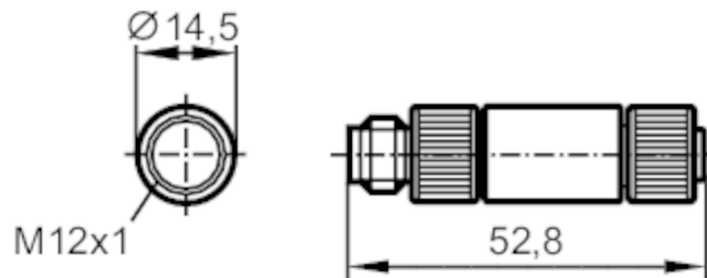

Application

Special feature Gold-plated contacts

Electrical data

Operating voltage [V] < 30 AC / < 36 DC
Max. current load total [A] 4

Operating conditions

Ambient temperature [°C] -40...85
Protection IP 68

Mechanical data


Weight [g] 22.68
Dimensions [mm] 14.5 x 14.5 x 52.8
Materials PVC
Material nut brass, nickel-plated / brass, nickel-plated

Remarks

Pack quantity 1 pcs.

Electrical connection - plug

Connector: 1 x M12, straight; Moulded body: PVC; Locking: brass, nickel-plated; Contacts: gold-plated

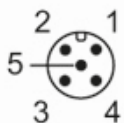

E18267




CAN bus terminating resistor

M12 PASSTHROUGH W/RESISTOR

Electrical connection - socket

Connector: 1 x M12, straight; Moulded body: PVC; Locking: brass, nickel-plated; Contacts: gold-plated

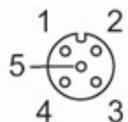

Connection

