


E20230



Fibre optic diffuse reflection sensor

FT-00-P-V-R1

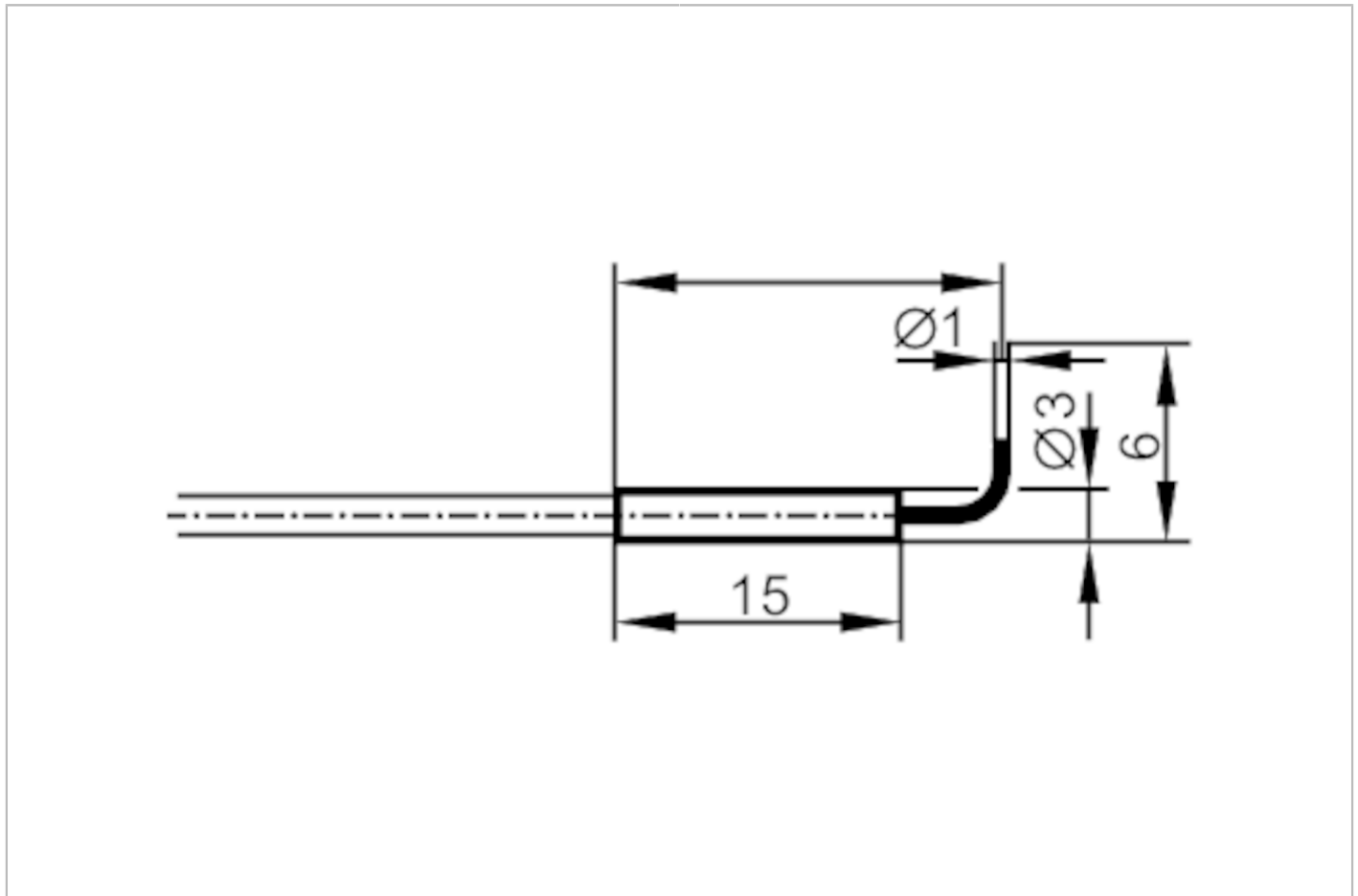

Application	
Function principle	Diffuse reflection sensor
Detection zone	
Range with fibre optic amplifier type	OKF; OUF; OOF
OKF	
Range fibre optics [mm]	6
OOF	
Range fibre optics [mm]	24
OUF	
Range fibre optics [mm]	6
Operating conditions	
Ambient temperature [°C]	-20...80

E20230



Fibre optic diffuse reflection sensor

FT-00-P-V-R1

Mechanical data	
Weight [g]	37
Version of sensing head	angled
Sensing head diameter [mm]	1
Total length [mm]	600
Min. bending radius [mm]	20
Fibre arrangement	⓪
Fibre material	glass
Fibre head material	stainless steel (1.4301 / 304)
Fibre sheath material	PVC
Accessories	
Accessories (supplied)	E20107
Remarks	
Pack quantity	1 pcs.