


# E20240



## Fibre optic diffuse reflection sensor

FT-30-A-A-R8/1M

Article no longer available - archive entry

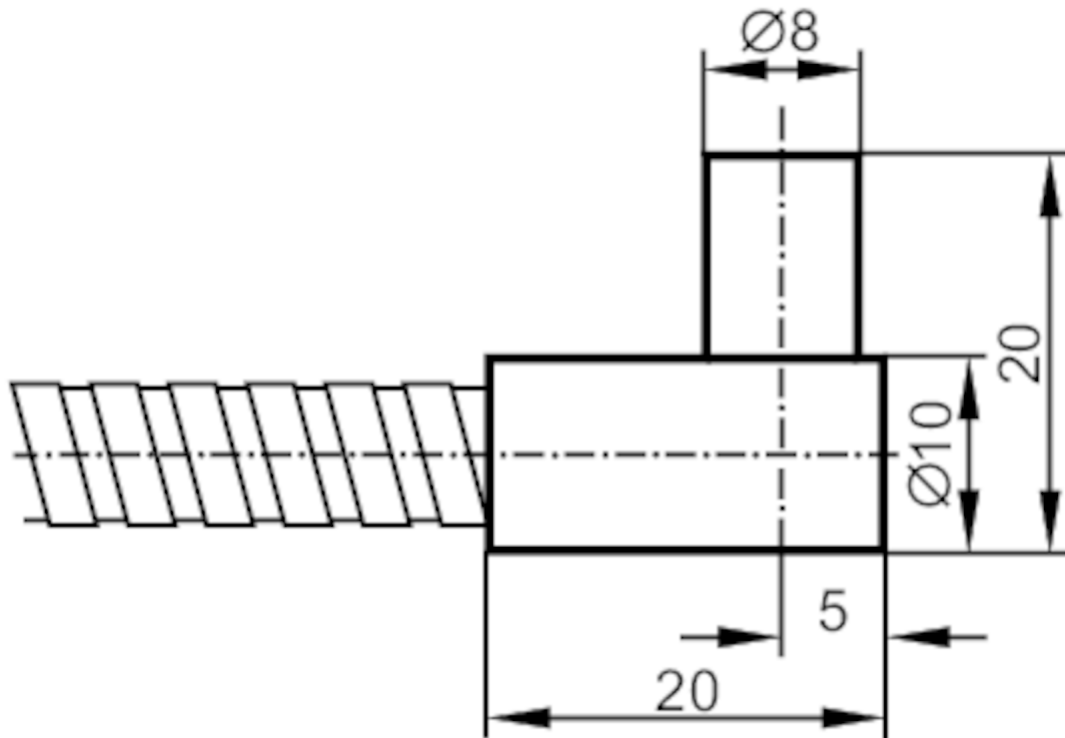

### Application

Function principle Diffuse reflection sensor

### Detection zone

Range with fibre optic amplifier type OIF

### OIF

Range fibre optics [mm] 70

### Operating conditions

Ambient temperature [°C] -40...290

### Mechanical data

Version of sensing head angled

Total length [mm] 1000

Min. bending radius [mm] 30

Materials Adapter: PA

Fibre material glass

Fibre head material aluminium

Fibre sheath material aluminium

### Remarks

Pack quantity 1 pcs.

# E20240

## Fibre optic diffuse reflection sensor

FT-30-A-A-R8/1M



Article no longer available - archive entry

---