


E20269



Fibre optic diffuse reflection sensor

FT-00-R3

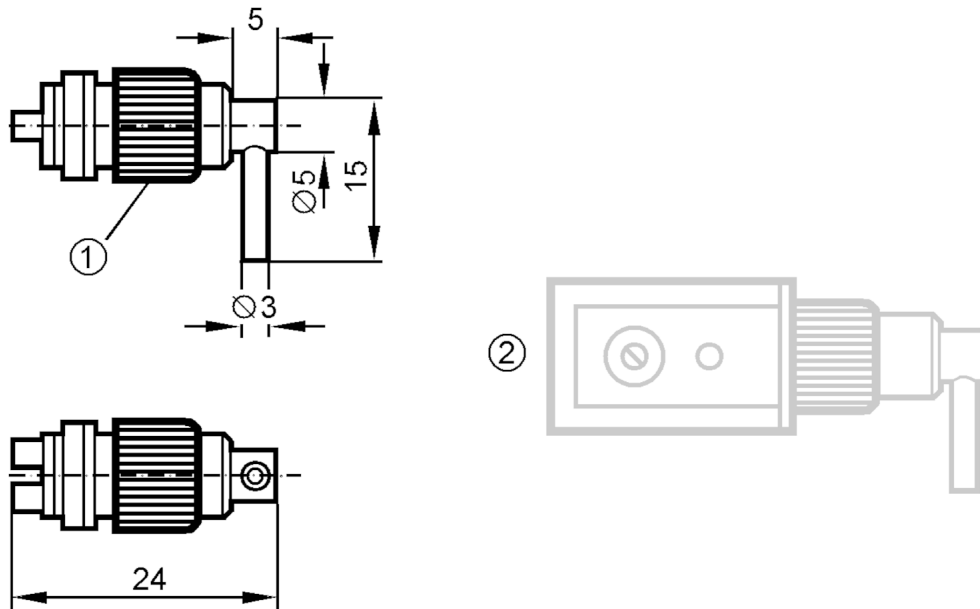

- 1 Lock nut
- 2 OKF with fibre optic

Application	
Function principle	Diffuse reflection sensor
Detection zone	
Range with fibre optic amplifier type	OKF
OKF	
Range fibre optics [mm]	25
Operating conditions	
Ambient temperature [°C]	-20...80
Mechanical data	
Weight [g]	14
Version of sensing head	angled; with adapter for direct mounting
Sensing head diameter [mm]	3
Total length [mm]	24
Fibre arrangement	Ⓢ
Materials	Lock nut: plastics
Fibre material	glass
Fibre head material	stainless steel (1.4305 / 303)
Remarks	
Pack quantity	1 pcs.