


# E10786



## Connecting cable with socket

ADOGF030MSS0005E03

Article no longer available - archive entry

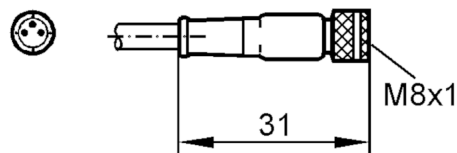

### Electrical data

Operating voltage [V]	< 60 AC / < 75 DC
Protection class	III

### Operating conditions

Ambient temperature [°C]	-25...90
Protection	IP 67

### Mechanical data

Materials	TPU
Material nut	brass, nickel-plated / brass, nickel-plated

### Remarks

Pack quantity	1 pcs.
---------------	--------

 
### Electrical connection

Cable: 5 m, PVC, orange, Ø 4.5 mm; 3 x 0.25 mm<sup>2</sup> (128 x Ø 0.05 mm)

### Electrical connection - socket

Connector: 1 x M8, straight; Moulded body: TPU; Locking: brass, nickel-plated

Connector: 1 x M8, straight; Moulded body: TPU; Locking: brass, nickel-plated




# E10786



## Connecting cable with socket

ADOGF030MSS0005E03

### Connection

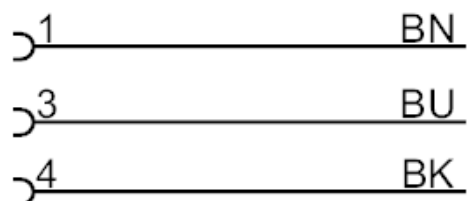

Core colours :

BK = black  
BN = brown  
BU = blue

Article no longer available - archive entry